

Hinge without pin

CHASB

Black or white plastic hinge

- **Polymer hinge without pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

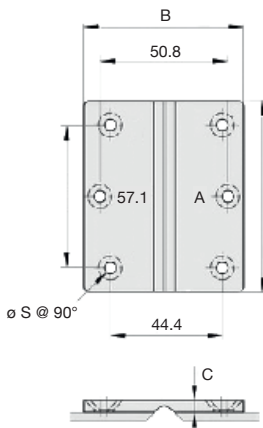

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

*Within the limits of available stock - Dimensions in mm

Our other products



Drylin® W rail, Rail



Worm and wheel gear reducer, up to 298 Nm



Free running conveyor roller, PVC



HTD Heavy duty timing pulley, HTD8 Cast



Single universal joint eco series, Low duty



Linear bearing with inclined ball tracks, Heavy loads / -20° +200°



 
Right angled gearbox, from 0.53 to 1.77




Manual locking clamp, Manual locking clamp LWL




303 Stainless steel compact ball pin,



Brush, silk

 

 Vertical toggle clamp, Vertical toggle clamp /



Steel spur gear, Steel 20NCD2

Complementary products



Hinge without pin, Plastic hinge



Roll of hinge without pin, Plastic hinge