

# Hinge without pin

## CHASB

## Black or white plastic hinge

- **Polymer hinge without pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:  
Polypropylene
- Tensile strength 180N/cm

### Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

### Use

- Ideal for horizontal use for hinging a hood



Tensile strength

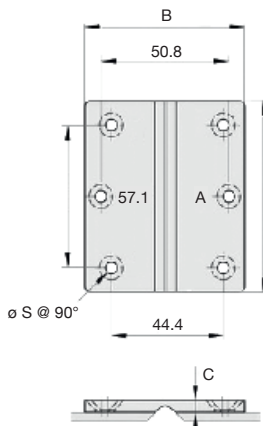

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

 
Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

\*Within the limits of available stock - Dimensions in mm

## Our other products



SHA\_PT  
Handwheel with handle, Polyamide



FTSN  
Supported shaft for linear guide, Steel shaft / Aluminium support



HG6-ECO  
Eco range Spur gear, Steel C45



BOX-TOR-C  
Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



ACLCHARJ  
Hinge for aluminium profile, Adjusts in 2 directions



RCC\_RCX  
Spherical tilt washer - DIN6319, concave



MHXred  
Reducing sleeve male/female, Hexagonal - stainless steel



PW\_PWG3  
Wheel - precision range, Bronze



PTA80ssEB  
Articulated foot with sheet metal base Ø80, Articulated foot



HLU  
Spoked handwheel without handle, Aluminium



GLB  
Small 6 lobe threaded handle - female, Technopolymer -



PTAF80-PAMF80  
Articulated fixable foot with pressed base Ø80, Ø 80

## Complementary products



CHAsb89  
Hinge without pin, Plastic hinge



CHAsb28  
Roll of hinge without pin, Plastic hinge