

Hinge without pin

Black or white plastic hinge

CHASB

- Polymer hinge without pin
- Fastening with screws or rivets.
- Working tempertaure range: -40° C to 80° C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention de material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strenght

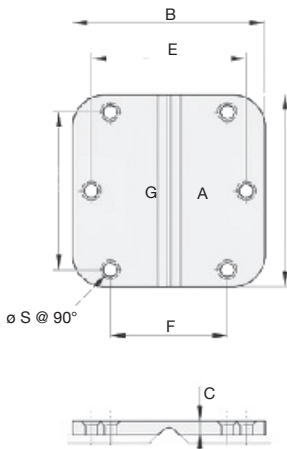

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight		Price per unit
									(g)	1 to 5	
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35		12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35		12,17 €

*Within the limits of available stock - Dimensions in mm

Our other products



TRM

Spur round rack, Steel
- module 1-6



CHAPAMss

Weld-on hinge with
flat end, Stainless
steel or Aluminium



WINGbrEcrou

Manually tightened
wing nut DIN315,
Brass DIN 315




SLB

Indexing plunger,
stainless steel



BAC110

Swivel storage bin,
Adjustable support

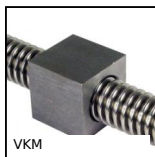

VKM

Square steel nut,
Steel - 1 thread



AKN

Bellows coupling
Gerwah®, from 22 to
180Nm



HW_HT

Half-rail guide, Rail



SRG

Adjustable latch
clamp with strike
plate, Stroke from
117,4mm to 128mm



IN1

Internal gear, Steel
20NCD2



PR85

Articulated foot Ø83,
Ø 83



PRF_SDD_1820

Support for Ø18 or
Ø20mm Prox
detector, Ø18 and
Ø20

Complementary products



CHAsb63

Hinge without pin,
Polymer pin hinge



CHAsb28

Roll of hinge without
pin, Plastic hinge