

Hinge without pin

Black or white plastic hinge

CHASB

- Polymer hinge without pin
- Fastening with screws or rivets.
- Working tempertaure range: -40° C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention de material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strenght

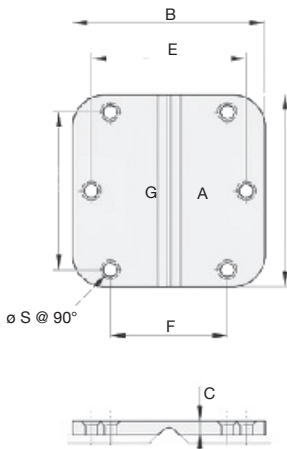

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight (g)		Price per unit
									1 to 5	6 to 20	21 to 50
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35		12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35		12,17 €

*Within the limits of available stock - Dimensions in mm

Our other products



ABL100005
Antistatic brush,
Standard



 
UGCG
Actuator guide kit,
Long housing



FGWA
End support, With
base



H2
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



H2
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



BPLE
Ball transfer unit push
fit, Light



PRF_GAL
Roller for aluminium
profile, Hollow roller
ø12



BPFLss
Pressed stainless
steel flange bearing,
Stainless steel



YG1
HEAVY DUTY spur
gear, Steel 35NCD6



BUT
Panel stop, Panel stop



GP75
Spring loaded toggle
latch, Standard



UGH50
H Type Guide units,
For Ø50 actuators

Complementary products



CHAsb63
Hinge without pin,
Polymer pin hinge



CHAsb28
Roll of hinge without
pin, Plastic hinge