

# Hinge without pin

Black or white plastic hinge

CHASB

- Polymer hinge without pin
- Fastening with screws or rivets.
- Working tempertaure range: -40° C to 80° C
- 270° opening angle
- Material:  
Polypropylene.
- Tensile strength 180N/cm

## Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention de material or possible impurities

## Use

- Ideal for horizontal use for hinging a hood



Tensile strenght

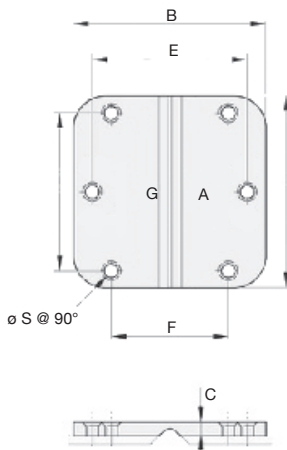

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight (g)	Price per unit
										1 to 5
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35	12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35	12,17 €

\*Within the limits of available stock - Dimensions in mm

## Our other products



DZYSS  
Stainless steel  
cylindrical stop,  
stainless steel



HRV  
V- rail guidance  
Simple Select®  
system, Rail with  
carriage



DOMI80  
Accessories, Plate



PRF\_PIV  
Internal hinge pin for  
aluminium profile,  
Internal hinge pin



BAGSS  
Stainless steel  
Clamping collar,  
Stainless steel



PW\_PWG25  
Worm - precision  
range, Steel



DOMI80  
Accessories, Turntable



CQA30  
Adjustment slide-  
system miniature, 30



SSB  
Stainless steel bevel  
gear, 1:1



ZB  
Shaft for linear  
guides, Hardened  
ground stainless steel



ZBconique  
Machined plastic  
bevel gear , 1:1



HLA28  
Right angle spiro  
bevel gearbox, Up to  
182Nm

## Complementary products



CHAsb63  
Hinge without pin,  
Polymer pin hinge



CHAsb28  
Roll of hinge without  
pin, Plastic hinge