

Non-removable pin hinge

CHASB

Black or white plastic hinge

- **Plastic hinge with non-removable pin**
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

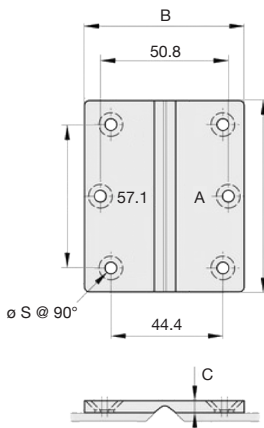

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Price	-5%	-10%	-10%	On request

Part number	A	B	C	ØS	Finishing	Weight (g)	Price per unit
							1 to 5
CHASB63-76/W	76.2	63.5	4.76	4.62	White	16	8,31 €
CHASB63-76/N	76.2	63.5	4.76	4.62	Black	16	8,31 €

*Within the limits of available stock - Dimensions in mm

Non-removable pin hinge

Black or white plastic hinge

CHASB

- Plastic hinge with non-removable pin
- Fastening with screws or rivets.
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
Polypropylene.
- Tensile strength 180N/cm

Advantages


- Good resistance to oils, solvents, seawater and most chemical agents
- Good fatigue resistance
- No knots, so no retention of material or possible impurities

Use

- Ideal for horizontal use for hinging a hood



Tensile strength

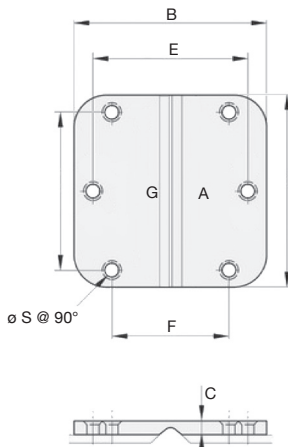

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Price	-5%	-10%	On request

Part number	A	B	C	E	F	G	ØS	Finishing	Weight (g)		Price per unit
									1 to 5	6 to 10	
CHASB89-89/W	88.9	88.9	6.35	71.4	54	73	6	White	35		12,17 €
CHASB89-89/N	88.9	88.9	6.35	71.4	54	73	6	Black	35		12,17 €

*Within the limits of available stock - Dimensions in mm

Non-removable roller pin hinge

CHASB

Black or white plastic hinge


- **Non-removable roller pin polymer hinge to be cut to length by the user**
- Offered in rolls of 15.25 meters
- Fastening by screws, rivets, nails or staples
- Working temperature range: -40°C to 80°C
- 270° opening angle
- Material:
 - Polypropylene
- Tensile strength 180N/cm

Advantages

- Good resistance to oils, solvents, seawater and most chemical agents
- Also, good fatigue resistance
- No knots, so no retention of material or possible impurities

Use


- Ideal for horizontal use for hinging a hood

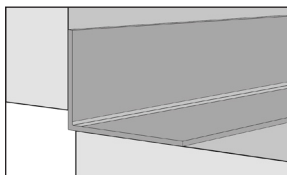

Typical application



Tensile strength

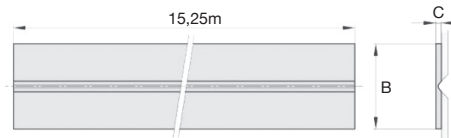


DISCOUNTS

Qty	1+	3+
Disc.	Price	On request

Part number	B	C	Finishing	Weight roll (g)	Price per unit 1 to 2
CHASB28-R/W	28.6	3.2	White	1050	350,67 €
CHASB28-R/N	28.6	3.2	Black	1050	350,67 €
CHASB38-R/W	38.1	3.2	White	1450	431,45 €
CHASB38-R/N	38.1	3.2	Black	1450	431,45 €

*Within the limits of available stock - Dimensions in mm

Our other products

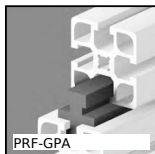

PRF-GPA
Guide for aluminium profile, Parallel rails



F7-SN
Multifunction display, Articulated support



MEB-ALI
Moulded plastic bevel gear (blue nylon), 1:1



T5M_T10M
T-type timing belt per metre, T5 Steel cored polyurethane



ACL-PLAngle
Connecting/joining, Angle connection



TS01_TW01
DryLin® T linear slide, up to 7000 N



GE14
Toggle latches, With padlock-holder



PCLA_T
Clamping lever - male, Plastic




CLG2-ALI
Spur gear, Moulded blue plastic (nylon)



PCS75K
Chain sprocket with hardened teeth,



DOMI80
Domino 80 adjustable slide, Slide DOMILINE

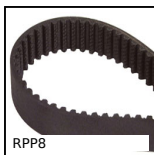

RPP8
RPP-heavy duty timing belt, RPP8

Complementary products



CHAsb63
Hinge without pin, Polymer pin hinge



CHAsb28
Roll of hinge without pin, Plastic hinge