




- **Universal hinge for nested door**
- 270° opening
- Fixing with M5, M6 or M8 countersunk screws according to DIN7991
- Molded hinge
- Materials:
 - Die cast zinc
 - Stainless steel pin

With countersunk holes

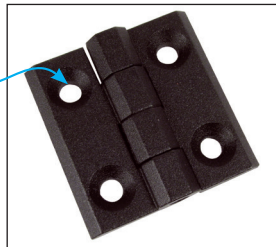

Advantages

- Beautiful finish

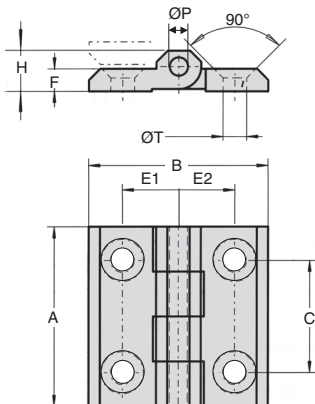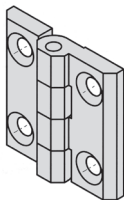

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
Square hinge											
CHA1056-U6	40	40	25	12,5	12,5	9	5	5,3	4	✓	12,32 €
CHA1056-U10	50	50	30	15	15	11,5	6	6,2	6	✓	12,83 €
CHA1056-U14	60	60	36	18	18	15	8	8,3	8	✓	16,03 €
Rectangular hinge											
CHA1056-U18	50	76	30	28	28	11	6	6,2	6	✓	30,73 €

*Depending on availability - Dimensions in mm

Our other products



NKIA

Combined bearing with inner ring, Axial load in one direction



UCFL

Cast iron flanged bearing, Cast iron



HLUT

Spoked handwheel with handle, Aluminium



EHD04

Internal epicyclic servo reducers, from 3.4 to 7 Nm



BH01

Single housed bearing, Bearing fitted with adhesive



SPIT

Floor mounting levelling plate, With anchoring point



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



BABPass

Hardened stainless steel ball pin with ring, With grip ring



PCP

Cell carrier assembly, Ready assembled



CHTRB

Single and dual output gearboxes, Up to 16,5 Nm



PSG08

Spur gear - precision range, Case hardened steel 20NCD2

Complementary products



CHAupa

Front hinge, 270°



CHAuss

Screwed hinge, 270°