




- **Universal hinge for nested door**
- 270° opening
- Fixing with M5, M6 or M8 countersunk screws according to DIN7991
- Molded hinge
- Materials:
  - Die cast zinc
  - Stainless steel pin

*With countersunk holes*

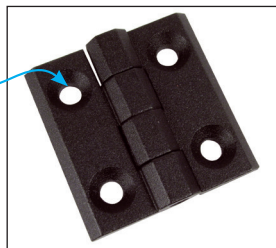

### Advantages

- Beautiful finish

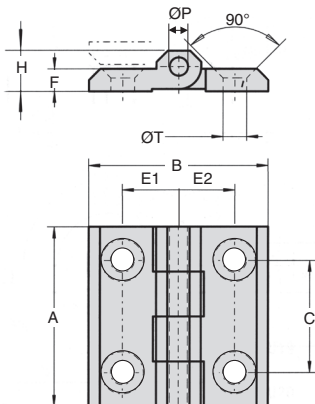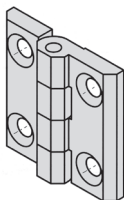

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
<b>Square hinge</b>											
CHA1056-U6	40	40	25	12,5	12,5	9	5	5,3	4	✓	12,32 €
CHA1056-U10	50	50	30	15	15	11,5	6	6,2	6	✓	12,83 €
CHA1056-U14	60	60	36	18	18	15	8	8,3	8	✓	16,03 €
<b>Rectangular hinge</b>											
CHA1056-U18	50	76	30	28	28	11	6	6,2	6	✓	30,73 €

\*Depending on availability - Dimensions in mm

## Our other products



ACL-PL

Joining plate for aluminium profile, joint plate - 176x86 mm



LVT

Miniature motorised actuator 2A, 2 amperes



PW\_PWG3

Wheel - precision range, Bronze



RAS

90° ball and socket joints DIN71802, Steel



 
RTT

Locking Assembly, Medium/high torque



M1

Worm and wheel set, Hardened steel



AC

Strike for toggle latch, 15mm



MDR

Dee shackle with eye bolt, Steel



GPBSS

Threaded spherical knob, Aluminium



BLHT50

Right angled gearbox, from 11.50 to 30 Nm



CFF\_SS

Female rod ends DIN ISO12240-4, Stainless



HAR9

Captive C washer, DIN 6371

## Complementary products



CHAupa

Front hinge, 270°



CHAuss

Screwed hinge, 270°