




# Molded polyamide face-mounted hinge ★★★ **Stock**

## CHAUPA With anchors

- Universal hinge for plug door
- 180° opening
- Nut fixing
- Molded hinge
- **Materials:**
  - Black polyamide
  - Stainless steel molded anchors
  - Stainless steel pin

### Advantages

- Beautiful finish

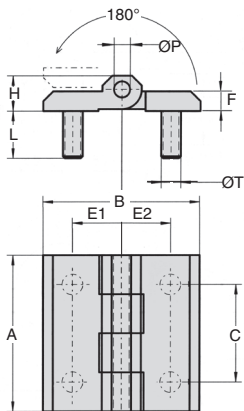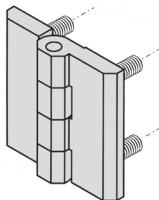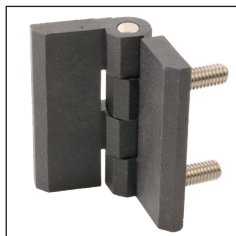

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 à 5
<b>Square hinge</b>											
CHA1056-U4PA	40	40	25	12,5	12,5	9	5	M5	12	-	13,91 €
CHA1056-U8PA	50	50	30	15	15	11,5	6	M6	15	✓	15,24 €

\*Depending on availability - Dimensions in mm

## Our other products



OP3\_14\_06  
Reducing sleeve for  
OP indicators,  
Reduction socket



NK40  
Drylin@N miniature  
guiding system, Width  
40 mm



VRM  
Female swivelling  
lifting rings, Female  
swivelling



M0  
Worm and wheel set,  
Bronze



HLUMss  
Revolving handle for  
handwheel, Stainless  
steel 316



SLB  
Indexing plunger,  
stainless steel




EBM  
Steel U bolt, Steel



G-ECO  
Eco range Spur gear,  
Steel C45



 GCB880  
Curved track for slat  
top chain, Ranges 880  
and 881



CTss  
Universal joint,  
telescopic, Inox, Light  
duty



DOMI50  
Domino 50 adjustable  
slide, Slide DOMILINE  
50



ACLAPA  
Magnetic stop for  
aluminium profile,  
Magnetic stop

## Complementary products



CHAu  
Screwed hinge, 270°



CHAUss  
Screwed hinge, 270°