




Stainless steel face-mounted hinge ★★★ Stock

CHAuss

With countersunk holes

- Universal hinge for nested door
- 270° opening
- Fixing with M5, M6, M8 countersunk screws according to DIN7991
- Raw finish
- Molded hinge
- Materials:
Stainless steel 316

stainless steel version

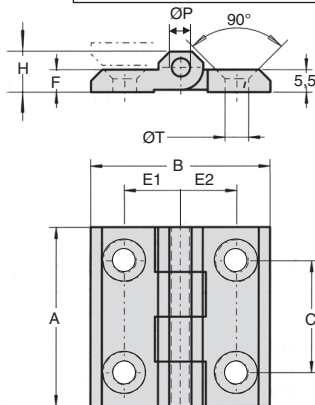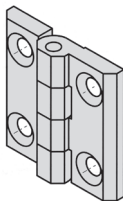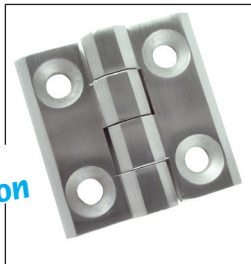

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	


Part number	A	B	C	E1	E2	H	F	ØT	ØP	Stock*	Price each 1 to 5
CHA1056-U6SS	40	40	25	12,5	12,5	9	5	5,3	4	✓	29,50 €
CHA1056-U10SS	50	50	30	15	15	11,5	6	6,2	6	✓	32,01 €
CHA1056-U14SS	60	60	36	18	18	15	8	8,3	8	✓	32,21 €

*Depending on availability - Dimensions in mm

Our other products



M0
Worm and wheel set,
Machined plastic
(delrin)

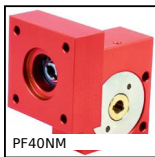

PF40NM
Worm and wheel gear
reducer, up to 18 Nm



H2
Crossed helical gear
crossed axis at 90°,
Steel 20NC D2



MF
Shock Absorber
-universal flange,
Universal fixing



RTT
Locking Assembly,
Medium/high torque



BVR
Adjustable screw stop,
Steel



WSSss
Symmetrical S shaped
hook stainless steel,
Stainless steel



VPR
Wing screw Hygienic
Usit®, Stainless steel



NDS20
Double cross clamp,
Crossed



UTKswc
Utilittrak® 3 wheels
carriage, Series V
precision steel wheel



BPFss
Pressed stainless
steel flange bearing,
Stainless steel



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -
Brass

Complementary products



CHAupa
Front hinge, 270°



CHAu
Screwed hinge, 270°