

# Socket-head screw **DIN 912**




## CHC<sub>ss</sub>

## Stainless steel A2

- Conforms to ISO 4762 and DIN 912
- Material: Stainless steel 302/304 - A2
- Hexagonal socket
- Sold by the packet

### Uses

- Suitable for harsh environments

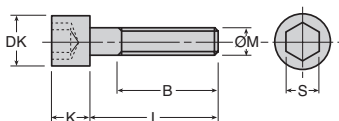

### DISCOUNTS

No. packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread	Total length L	Pitch	B	DK	K	S	Qty per packet	Stock*	Price per packet
CHC1.6-5/SS/B	M1,6	0,35	5	-	3,0	1,6	1,5	200	-	13,49 €
CHC1.6-8/SS/B	M1,6	0,35	8	-	3,0	1,6	1,5	200	✓	13,20 €
CHC1.6-10/SS/B	M1,6	0,35	10	-	3,0	1,6	1,5	200	✓	16,42 €
CHC2-4/SS/B	M2	0,40	4	-	3,8	2,0	1,5	500	-	13,56 €
CHC2-5/SS/B	M2	0,40	5	-	3,8	2,0	1,5	500	✓	18,20 €
CHC2-6/SS/B	M2	0,40	6	-	3,8	2,0	1,5	500	✓	19,80 €
CHC2-8/SS/B	M2	0,40	8	-	3,8	2,0	1,5	500	✓	22,49 €
CHC2-10/SS/B	M2	0,40	10	-	3,8	2,0	1,5	500	✓	18,92 €
CHC2-12/SS/B	M2	0,40	12	-	3,8	2,0	1,5	500	✓	21,95 €
CHC2-20/SS/B	M2	0,40	20	-	3,8	2,0	1,5	500	✓	29,63 €
CHC2.5-4/SS/B	M2,5	0,45	4	-	4,5	2,5	2,0	500	-	15,35 €
CHC2.5-5/SS/B	M2,5	0,45	5	-	4,5	2,5	2,0	500	-	14,81 €
CHC2.5-6/SS/B	M2,5	0,45	6	-	4,5	2,5	2,0	500	-	15,70 €
CHC2.5-8/SS/B	M2,5	0,45	8	-	4,5	2,5	2,0	500	✓	16,23 €
CHC2.5-10/SS/B	M2,5	0,45	10	-	4,5	2,5	2,0	500	✓	16,95 €
CHC2.5-16/SS/B	M2,5	0,45	16	-	4,5	2,5	2,0	500	✓	22,84 €
CHC2.5-20/SS/B	M2,5	0,45	20	-	4,5	2,5	2,0	500	✓	26,41 €
CHC3-6/SS/B	M3	0,50	6	-	5,5	3,0	2,5	1000	✓	23,56 €
CHC3-8/SS/B	M3	0,50	8	-	5,5	3,0	2,5	1000	✓	22,49 €
CHC3-10/SS/B	M3	0,50	10	-	5,5	3,0	2,5	1000	✓	26,41 €
CHC3-12/SS/B	M3	0,50	12	-	5,5	3,0	2,5	1000	✓	25,70 €
CHC3-16/SS/B	M3	0,50	16	-	5,5	3,0	2,5	1000	✓	30,34 €
CHC3-20/SS/B	M3	0,50	20	-	5,5	3,0	2,5	1000	✓	37,12 €
CHC3-25/SS/B	M3	0,50	25	18	5,5	3,0	2,5	1000	✓	44,26 €
CHC3-30/SS/B	M3	0,50	30	18	5,5	3,0	2,5	1000	-	52,83 €
CHC3-35/SS/B	M3	0,50	35	18	5,5	3,0	2,5	500	-	28,91 €
CHC4-6/SS/B	M4	0,70	6	-	7,0	4,0	3,0	500	✓	15,52 €
CHC4-8/SS/B	M4	0,70	8	-	7,0	4,0	3,0	500	✓	21,23 €
CHC4-10/SS/B	M4	0,70	10	-	7,0	4,0	3,0	500	✓	16,59 €

\*Depending on availability - Dimensions in mm

## DISCOUNTS

No. packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread		Total					Qty per packet	Stock*	Price per packet
	ØM	Pitch	length L	B	DK	K	S			
CHC4-12/SS/B	M4	0,70	12	-	7,0	4	3	500	✓	17,66 €
CHC4-16/SS/B	M4	0,70	16	-	7,0	4	3	500	✓	20,34 €
CHC4-20/SS/B	M4	0,70	20	-	7,0	4	3	500	✓	25,84 €
CHC4-25/SS/B	M4	0,70	25	-	7,0	4	3	500	✓	24,99 €
CHC4-30/SS/B	M4	0,70	30	20	7,0	4	3	500	✓	35,51 €
CHC4-35/SS/B	M4	0,70	35	20	7,0	4	3	500	✓	34,98 €
CHC4-40/SS/B	M4	0,70	40	20	7,0	4	3	500	✓	41,58 €
CHC4-50/SS/B	M4	0,70	50	20	7,0	4	3	200	✓	21,49 €
CHC5-8/SS/B	M5	0,80	8	-	8,5	5	4	500	✓	26,94 €
CHC5-10/SS/B	M5	0,80	10	-	8,5	5	4	500	✓	32,13 €
CHC5-12/SS/B	M5	0,80	12	-	8,5	5	4	500	✓	25,16 €
CHC5-16/SS/B	M5	0,80	16	-	8,5	5	4	500	✓	36,05 €
CHC5-20/SS/B	M5	0,80	20	-	8,5	5	4	500	✓	38,01 €
CHC5-25/SS/B	M5	0,80	25	-	8,5	5	4	500	✓	34,98 €
CHC5-30/SS/B	M5	0,80	30	22	8,5	5	4	500	✓	40,15 €
CHC5-35/SS/B	M5	0,80	35	22	8,5	5	4	500	✓	55,69 €
CHC5-40/SS/B	M5	0,80	40	22	8,5	5	4	500	✓	53,36 €
CHC5-50/SS/B	M5	0,80	50	22	8,5	5	4	200	✓	28,34 €
CHC6-8/SS/B	M6	1,00	8	-	10,0	6	5	500	-	50,33 €
CHC6-10/SS/B	M6	1,00	10	-	10,0	6	5	500	✓	33,01 €
CHC6-12/SS/B	M6	1,00	12	-	10,0	6	5	500	✓	32,66 €
CHC6-16/SS/B	M6	1,00	16	-	10,0	6	5	500	✓	39,62 €
CHC6-20/SS/B	M6	1,00	20	-	10,0	6	5	500	✓	41,05 €
CHC6-25/SS/B	M6	1,00	25	-	10,0	6	5	500	✓	48,55 €
CHC6-30/SS/B	M6	1,00	30	-	10,0	6	5	500	✓	50,69 €
CHC6-35/SS/B	M6	1,00	35	24	10,0	6	5	500	✓	67,64 €
CHC6-40/SS/B	M6	1,00	40	24	10,0	6	5	500	✓	75,68 €
CHC6-50/SS/B	M6	1,00	50	24	10,0	6	5	500	✓	79,96 €
CHC6-60/SS/B	M6	1,00	60	24	10,0	6	5	500	-	92,60 €
CHC6-80/SS/B	M6	1,00	80	24	10,0	6	5	100	✓	34,70 €
CHC6-100/SS/B	M6	1,00	100	24	10,0	6	5	100	✓	45,33 €
CHC8-10/SS/B	M8	1,25	10	-	13,0	8	6	200	-	47,62 €
CHC8-16/SS/B	M8	1,25	16	-	13,0	8	6	200	✓	30,34 €
CHC8-20/SS/B	M8	1,25	20	-	13,0	8	6	200	✓	35,12 €
CHC8-25/SS/B	M8	1,25	25	-	13,0	8	6	200	✓	36,69 €
CHC8-30/SS/B	M8	1,25	30	-	13,0	8	6	200	✓	42,19 €
CHC8-35/SS/B	M8	1,25	35	-	13,0	8	6	200	✓	43,76 €
CHC8-40/SS/B	M8	1,25	40	28	13,0	8	6	200	✓	59,83 €
CHC8-50/SS/B	M8	1,25	50	28	13,0	8	6	200	✓	71,75 €
CHC8-60/SS/B	M8	1,25	60	28	13,0	8	6	200	✓	82,68 €
CHC8-80/SS/B	M8	1,25	80	28	13,0	8	6	200	-	102,53 €
CHC10-20/SS/B	M10	1,50	20	-	16,0	10	8	100	✓	30,01 €
CHC10-25/SS/B	M10	1,50	25	-	16,0	10	8	100	✓	35,34 €
CHC10-30/SS/B	M10	1,50	30	-	16,0	10	8	100	✓	36,15 €
CHC10-40/SS/B	M10	1,50	40	-	16,0	10	8	100	✓	43,44 €
CHC10-50/SS/B	M10	1,50	50	32	16,0	10	8	100	-	47,90 €

\*Depending on availability - Dimensions in mm

## Our other products



BIMSS

Indexing plunger mini,  
miniature - Stainless  
steel



H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



MHQMEP

Arm with rotating  
handle, Square bore




SH1

Parallel axis helical  
gear, Machined plastic  
(delrin)



M0

 Worm and wheel set,  
Machined plastic  
(delrin)



PO

Pull handle - Multi-  
sector, Smooth hole



CHAR7520

Spring hinge, screwed



SH0

Parallel axis helical  
gear, Steel 20NCD2



CLSCLP\_SS

Clevis components,  
short version,  
Stainless steel - short



VDS

Sliding lock  
adjustment system,  
Sliding lock for oblong



SKM

Hexagonal steel nut,  
Steel - 1 thread



WING

Manually tightened  
wing nut, Steel (ANSI  
B18-17)

## Complementary products



SHN

Hexagonal nut  
DIN934, A2 Stainless  
steel



NIN

Self-locking nut, A2  
Stainless steel



SHW

Plain washer, A2  
Stainless steel



CHC

Socket headed screw,  
Steel class 12.19