

Socket-head screw **DIN 912**




CHC_{ss}

Stainless steel A2

- **Conforms to ISO 4762 and DIN 912**
- Material: Stainless steel 302/304 - A2
- Hexagonal socket
- Sold by the packet

Uses

- Suitable for harsh environments

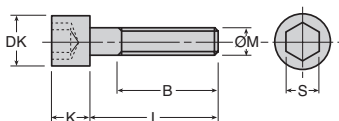

DISCOUNTS

No. packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread	Total length L	Pitch	B	DK	K	S	Qty per packet	Stock*	Price per packet
CHC1.6-5/SS/B	M1,6	0,35	5	-	3,0	1,6	1,5	200	-	13,49 €
CHC1.6-8/SS/B	M1,6	0,35	8	-	3,0	1,6	1,5	200	✓	13,20 €
CHC1.6-10/SS/B	M1,6	0,35	10	-	3,0	1,6	1,5	200	✓	16,42 €
CHC2-4/SS/B	M2	0,40	4	-	3,8	2,0	1,5	500	-	13,56 €
CHC2-5/SS/B	M2	0,40	5	-	3,8	2,0	1,5	500	✓	18,20 €
CHC2-6/SS/B	M2	0,40	6	-	3,8	2,0	1,5	500	✓	19,80 €
CHC2-8/SS/B	M2	0,40	8	-	3,8	2,0	1,5	500	✓	22,49 €
CHC2-10/SS/B	M2	0,40	10	-	3,8	2,0	1,5	500	✓	18,92 €
CHC2-12/SS/B	M2	0,40	12	-	3,8	2,0	1,5	500	✓	21,95 €
CHC2-20/SS/B	M2	0,40	20	-	3,8	2,0	1,5	500	✓	29,63 €
CHC2.5-4/SS/B	M2,5	0,45	4	-	4,5	2,5	2,0	500	-	15,35 €
CHC2.5-5/SS/B	M2,5	0,45	5	-	4,5	2,5	2,0	500	-	14,81 €
CHC2.5-6/SS/B	M2,5	0,45	6	-	4,5	2,5	2,0	500	-	15,70 €
CHC2.5-8/SS/B	M2,5	0,45	8	-	4,5	2,5	2,0	500	✓	16,23 €
CHC2.5-10/SS/B	M2,5	0,45	10	-	4,5	2,5	2,0	500	✓	16,95 €
CHC2.5-16/SS/B	M2,5	0,45	16	-	4,5	2,5	2,0	500	✓	22,84 €
CHC2.5-20/SS/B	M2,5	0,45	20	-	4,5	2,5	2,0	500	✓	26,41 €
CHC3-6/SS/B	M3	0,50	6	-	5,5	3,0	2,5	1000	✓	23,56 €
CHC3-8/SS/B	M3	0,50	8	-	5,5	3,0	2,5	1000	✓	22,49 €
CHC3-10/SS/B	M3	0,50	10	-	5,5	3,0	2,5	1000	✓	26,41 €
CHC3-12/SS/B	M3	0,50	12	-	5,5	3,0	2,5	1000	✓	25,70 €
CHC3-16/SS/B	M3	0,50	16	-	5,5	3,0	2,5	1000	✓	30,34 €
CHC3-20/SS/B	M3	0,50	20	-	5,5	3,0	2,5	1000	✓	37,12 €
CHC3-25/SS/B	M3	0,50	25	18	5,5	3,0	2,5	1000	✓	44,26 €
CHC3-30/SS/B	M3	0,50	30	18	5,5	3,0	2,5	1000	-	52,83 €
CHC3-35/SS/B	M3	0,50	35	18	5,5	3,0	2,5	500	-	28,91 €
CHC4-6/SS/B	M4	0,70	6	-	7,0	4,0	3,0	500	✓	15,52 €
CHC4-8/SS/B	M4	0,70	8	-	7,0	4,0	3,0	500	✓	21,23 €
CHC4-10/SS/B	M4	0,70	10	-	7,0	4,0	3,0	500	✓	16,59 €

*Depending on availability - Dimensions in mm

DISCOUNTS

No. packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread		Total					Qty per packet	Stock*	Price per packet
	ØM	Pitch	length	L	B	DK	K			
CHC4-12/SS/B	M4	0,70	12	-	7,0	4	3	500	✓	17,66 €
CHC4-16/SS/B	M4	0,70	16	-	7,0	4	3	500	✓	20,34 €
CHC4-20/SS/B	M4	0,70	20	-	7,0	4	3	500	✓	25,84 €
CHC4-25/SS/B	M4	0,70	25	-	7,0	4	3	500	✓	24,99 €
CHC4-30/SS/B	M4	0,70	30	20	7,0	4	3	500	✓	35,51 €
CHC4-35/SS/B	M4	0,70	35	20	7,0	4	3	500	✓	34,98 €
CHC4-40/SS/B	M4	0,70	40	20	7,0	4	3	500	✓	41,58 €
CHC4-50/SS/B	M4	0,70	50	20	7,0	4	3	200	✓	21,49 €
CHC5-8/SS/B	M5	0,80	8	-	8,5	5	4	500	✓	26,94 €
CHC5-10/SS/B	M5	0,80	10	-	8,5	5	4	500	✓	32,13 €
CHC5-12/SS/B	M5	0,80	12	-	8,5	5	4	500	✓	25,16 €
CHC5-16/SS/B	M5	0,80	16	-	8,5	5	4	500	✓	36,05 €
CHC5-20/SS/B	M5	0,80	20	-	8,5	5	4	500	✓	38,01 €
CHC5-25/SS/B	M5	0,80	25	-	8,5	5	4	500	✓	34,98 €
CHC5-30/SS/B	M5	0,80	30	22	8,5	5	4	500	✓	40,15 €
CHC5-35/SS/B	M5	0,80	35	22	8,5	5	4	500	✓	55,69 €
CHC5-40/SS/B	M5	0,80	40	22	8,5	5	4	500	✓	53,36 €
CHC5-50/SS/B	M5	0,80	50	22	8,5	5	4	200	✓	28,34 €
CHC6-8/SS/B	M6	1,00	8	-	10,0	6	5	500	-	50,33 €
CHC6-10/SS/B	M6	1,00	10	-	10,0	6	5	500	✓	33,01 €
CHC6-12/SS/B	M6	1,00	12	-	10,0	6	5	500	✓	32,66 €
CHC6-16/SS/B	M6	1,00	16	-	10,0	6	5	500	✓	39,62 €
CHC6-20/SS/B	M6	1,00	20	-	10,0	6	5	500	✓	41,05 €
CHC6-25/SS/B	M6	1,00	25	-	10,0	6	5	500	✓	48,55 €
CHC6-30/SS/B	M6	1,00	30	-	10,0	6	5	500	✓	50,69 €
CHC6-35/SS/B	M6	1,00	35	24	10,0	6	5	500	✓	67,64 €
CHC6-40/SS/B	M6	1,00	40	24	10,0	6	5	500	✓	75,68 €
CHC6-50/SS/B	M6	1,00	50	24	10,0	6	5	500	✓	79,96 €
CHC6-60/SS/B	M6	1,00	60	24	10,0	6	5	500	-	92,60 €
CHC6-80/SS/B	M6	1,00	80	24	10,0	6	5	100	✓	34,70 €
CHC6-100/SS/B	M6	1,00	100	24	10,0	6	5	100	✓	45,33 €
CHC8-10/SS/B	M8	1,25	10	-	13,0	8	6	200	-	47,62 €
CHC8-16/SS/B	M8	1,25	16	-	13,0	8	6	200	✓	30,34 €
CHC8-20/SS/B	M8	1,25	20	-	13,0	8	6	200	✓	35,12 €
CHC8-25/SS/B	M8	1,25	25	-	13,0	8	6	200	✓	36,69 €
CHC8-30/SS/B	M8	1,25	30	-	13,0	8	6	200	✓	42,19 €
CHC8-35/SS/B	M8	1,25	35	-	13,0	8	6	200	✓	43,76 €
CHC8-40/SS/B	M8	1,25	40	28	13,0	8	6	200	✓	59,83 €
CHC8-50/SS/B	M8	1,25	50	28	13,0	8	6	200	✓	71,75 €
CHC8-60/SS/B	M8	1,25	60	28	13,0	8	6	200	✓	82,68 €
CHC8-80/SS/B	M8	1,25	80	28	13,0	8	6	200	-	102,53 €
CHC10-20/SS/B	M10	1,50	20	-	16,0	10	8	100	✓	30,01 €
CHC10-25/SS/B	M10	1,50	25	-	16,0	10	8	100	✓	35,34 €
CHC10-30/SS/B	M10	1,50	30	-	16,0	10	8	100	✓	36,15 €
CHC10-40/SS/B	M10	1,50	40	-	16,0	10	8	100	✓	43,44 €
CHC10-50/SS/B	M10	1,50	50	32	16,0	10	8	100	-	47,90 €

*Depending on availability - Dimensions in mm

Our other products



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with tapped ins...



SMLS

Linear table, For small lengths



PRF_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths



SUPTOOL

Installation tools for clamping hub, For hexagonal clamping hub



BDM

Pin for magnetic bush, Fast and light magnetic locking



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



CSSSS

Stainless steel spherical bearing, Stainless steel / PTFE



GCH

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



SVT20

Screwjack with travelling screw, with translating screw



CHA35

Hinge for aluminium profile, Hinge



CHTRP

Single and dual output gearboxes, Up to 75,7 Nm



RNAST

Cam follower without axial guide, Without interior ring

Complementary products



SHN

Hexagonal nut DIN934, A2 Stainless steel



NIN

Self-locking nut, A2 Stainless steel



SHW

Plain washer, A2 Stainless steel



CHC

Socket headed screw, Steel class 12.19