

Steel or stainless steel invisible hinge

Sta

CHINV For nested doors or surface mounted doors



- Invisible hinge with connecting rods
- 90° opening
- Material:
 - Zinc-plated steel with 430 stainless steel pin and rod
 - Stainless steel 316L raw

Advantage


- Invisible when the door is closed

Mounting



- Flush or surface mounting
- Right- or left-hand mounting
- Vertical or horizontal mounting

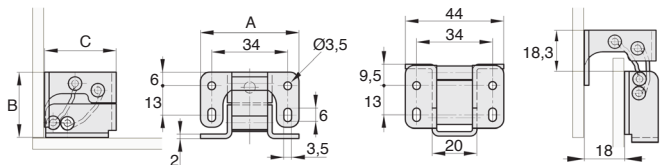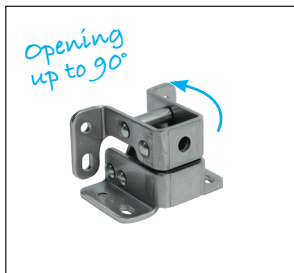

Hanging a built-in door

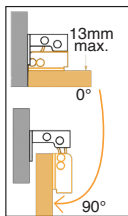

Hanging a surface mounted door

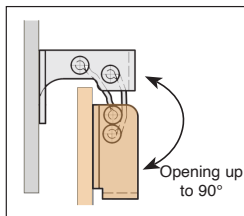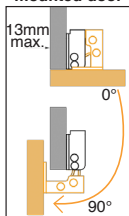

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-----------|-----|------|------|------------|
| Disc. Net | -5% | -10% | -10% | On request |

| Part number | Material | A | B | C | Weight (g) | Stock* | Price each 1 to 5 |
|---------------|----------------------|----|----|----|------------|--------|-------------------|
| CHINV-4429 | Steel | 44 | 29 | 32 | 64 | ✓ | 22,21 € |
| CHINV-4429/SS | Stainless steel 316L | 44 | 29 | 32 | 64 | - | 31,04 € |

*Depending on availability - Dimensions in mm

Steel or stainless steel invisible hinge

CHINV For nested doors or surface mounted doors





- Concealed hinges (Medium size)
- 125° opening
- Material:
 - Steel zinc plated or 316L stainless steel raw
 - Links in aluminium
 - Pin in zinc plated steel or in 304Cu stainless steel

Advantage

- Invisible when the door is closed

Assembly

- For nested doors or surface mounted doors
- LH or RH options
- For horizontal or vertical applications.
- Opening angle differs according to door thickness:
 - For thickness up to 10 mm: opening angle of 125°
 - 15 mm thickness: opening angle of 115°
 - 20 mm thickness: opening angle of 108°

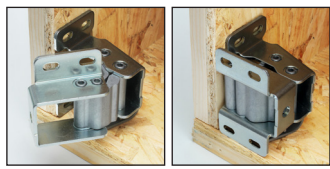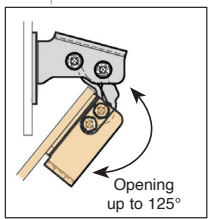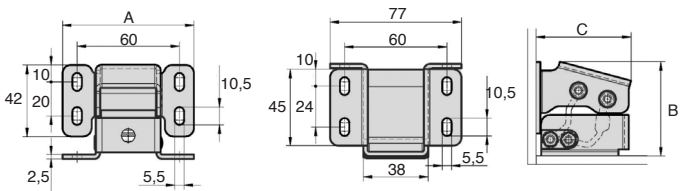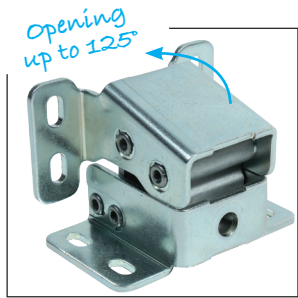

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 6+ | 20+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | Material | A | B | C | Weight (g) | Stock* | Price each |
|---------------|-----------------|----|------|------|------------|--------|------------|
| CHINV-7755 | Steel | 77 | 55,2 | 54,0 | 250 | - | 18,38 € |
| CHINV-7755/SS | Stainless steel | 77 | 55,2 | 54,0 | 250 | - | 32,93 € |

*Depending on availability - Dimensions in mm

Our other products



MHMEP
Arm with rotating handle, Prebored



BZY_SS
Stainless steel cylindrical elastomount, Stainless steel



DOMI80
Accessories, Fixing kit



VEL
Self-gripping cable strip, electric and pneumatic cables



RVM14
Manual worm and wheel gearbox, Worm/wheel



SUPTOOL
Installation tools for clamping hub, For hexagonal clamping hub



MCL
Cylindrical threaded sleeve, Cylindrical - steel



PCF2
Compact flexible mount, Oval base plate



DOMI50
Accessories, Turntable



HTD8M-BAR
HTD type tooth bar stock, HTD8



RFV40
Stainless steel worm and wheel gearbox, up to 47 Nm



BWU
Compact precision slide, from 1510 N to 10500 N

Complementary products



CHINV
Invisible hinge, Invisible - 90° opening



CHINV2
Invisible hinge, Invisible - Opening up to 125°



CHA1056_U4
Screw-in hinge, Section 40X40