

# Steel or stainless steel invisible hinge

Sta

## CHINV For nested doors or surface mounted doors



- Invisible hinge with connecting rods
- 90° opening
- Material:  
Zinc-plated steel with 430 stainless steel pin and rod  
Stainless steel 316L raw

### Advantage


- Invisible when the door is closed

### Mounting



- Flush or surface mounting
- Right- or left-hand mounting
- Vertical or horizontal mounting

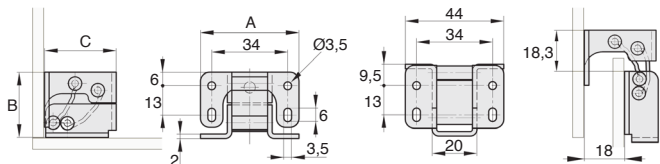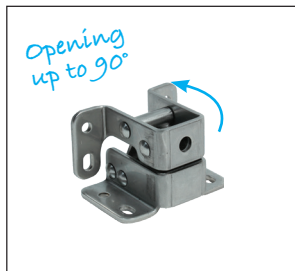

#### Hanging a built-in door

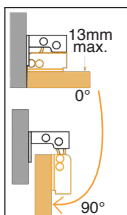

#### Hanging a surface mounted door

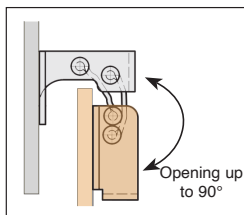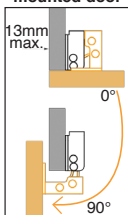

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Net	-5%	-10%	On request	

Part number	Material	A	B	C	Weight (g)	Stock*	Price each
CHINV-4429	Steel	44	29	32	64	✓	22,21 €
CHINV-4429/SS	Stainless steel 316L	44	29	32	64	-	31,04 €

\*Depending on availability - Dimensions in mm

# Steel or stainless steel invisible hinge

## CHINV For nested doors or surface mounted doors





- Concealed hinges (Medium size)
- 125° opening
- Material:
  - Steel zinc plated or 316L stainless steel raw
  - Links in aluminium
  - Pin in zinc plated steel or in 304Cu stainless steel

### Advantage

- Invisible when the door is closed

### Assembly

- For nested doors or surface mounted doors
- LH or RH options
- For horizontal or vertical applications.
- Opening angle differs according to door thickness:
  - For thickness up to 10 mm: opening angle of 125°
  - 15 mm thickness: opening angle of 115°
  - 20 mm thickness: opening angle of 108°

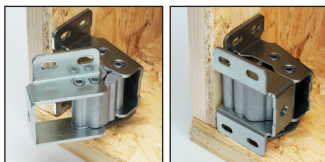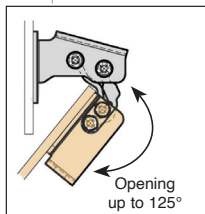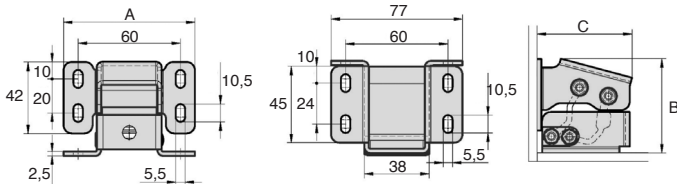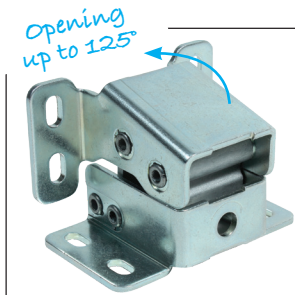

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Material	A	B	C	Weight (g)	Price each	
						Stock*	1 to 5
CHINV-7755	Steel	77	55,2	54,0	250	-	18,38 €
CHINV-7755/SS	Stainless steel	77	55,2	54,0	250	-	32,93 €

\*Depending on availability - Dimensions in mm

## Our other products



UGPL

Actuator guide kit,  
Long bearing



SMLS

Linear table, For small  
lengths



HCA

Magnetic screw with  
socket, Steel



DFG

Flat suction cup,  
silicon



PCH

Knob for gripping,  
Mushroom



MRA

Quick link, Steel



BPM-Z

Plastic slotted spring  
plunger with ball tip,  
Plastic body +  
plastic...



RURt

Swivel castor with  
central hole,  
Polyurethane -  
Aluminium rim (Free



G2

Steel spur gear, Steel  
20NCD2



BLHT60

Right angled gearbox,  
from 26 to 70 Nm



MEP

Revolving handle for  
handwheel, Fixed



EMR

Fast-locking knurled  
nut, Knurled

## Complementary products



CHINV

Invisible hinge,  
Invisible - 90° opening



CHINV2

Invisible hinge,  
Invisible - Opening up  
to 125°



CHA1056\_U4

Screw-in hinge,  
Section 40X40