

Steel or stainless steel invisible hinge

Sta

CHINV For nested doors or surface mounted doors



- Invisible hinge with connecting rods
- 90° opening
- Material:
 - Zinc-plated steel with 430 stainless steel pin and rod
 - Stainless steel 316L raw

Advantage


- Invisible when the door is closed

Mounting



- Flush or surface mounting
- Right- or left-hand mounting
- Vertical or horizontal mounting

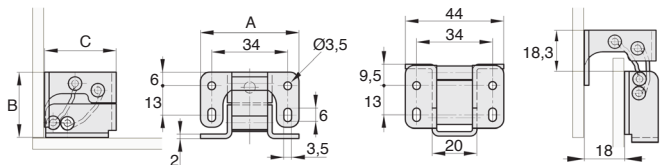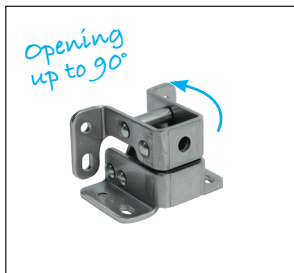

Hanging a built-in door

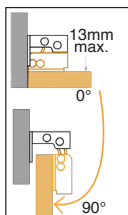

Hanging a surface mounted door

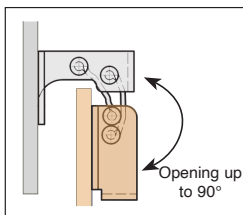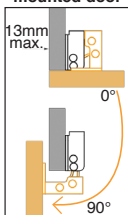

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Net	-5%	-10%	-10%	On request

Part number	Material	A	B	C	Weight (g)	Stock*	Price each 1 to 5
CHINV-4429	Steel	44	29	32	64	✓	22,21 €
CHINV-4429/SS	Stainless steel 316L	44	29	32	64	-	31,04 €

*Depending on availability - Dimensions in mm

Steel or stainless steel invisible hinge

CHINV For nested doors or surface mounted doors





- Concealed hinges (Medium size)
- 125° opening
- Material:
 - Steel zinc plated or 316L stainless steel raw
 - Links in aluminium
 - Pin in zinc plated steel or in 304Cu stainless steel

Advantage

- Invisible when the door is closed

Assembly

- For nested doors or surface mounted doors
- LH or RH options
- For horizontal or vertical applications.
- Opening angle differs according to door thickness:
 - For thickness up to 10 mm: opening angle of 125°
 - 15 mm thickness: opening angle of 115°
 - 20 mm thickness: opening angle of 108°

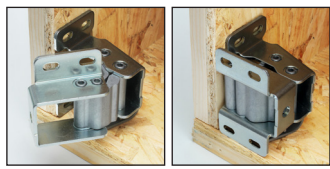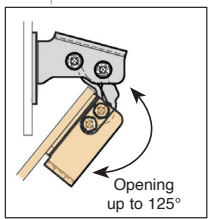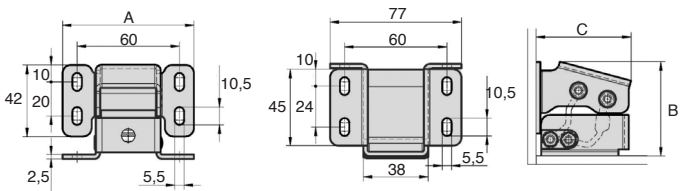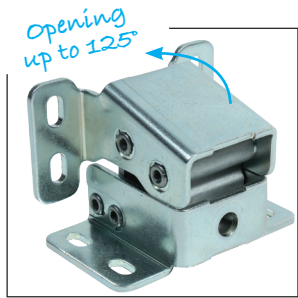

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Material	A	B	C	Weight (g)	Stock*	Price each
CHINV-7755	Steel	77	55,2	54,0	250	-	18,38 €
CHINV-7755/SS	Stainless steel	77	55,2	54,0	250	-	32,93 €

*Depending on availability - Dimensions in mm

Our other products



PPD

Indexing plunger for sheets, For sheet metal



ZB

Shaft for linear guides, Hardened ground stainless steel



UCP_SS

Stainless steel pillow block bearing, Stainless steel



AC

Strike for toggle latch, 15mm



DB

Steel bevel gear, 2:1



T2

T type timing belt, T2.5 Steel cored polyurethane



PRF-GPB

Guide for aluminium profile, Rail for 8mm wide slots



B_ECO

Eco. range steel bevel gear, 1:1



T10courroie

T type timing belt, T10 Steel cored polyurethane



ESCON

Speed controller 5A, 5A



ZBconique

Machined plastic bevel gear, 1:1



ETQ

Magnetic label holder for aluminium profile, Label holder

Complementary products



CHINV

Invisible hinge, Invisible - Opening up to 90°



CHINV2

Invisible hinge, Invisible - Opening up to 125°