



- Invisible hinge with connecting rods
- 90° opening
- Material:
 - Zinc-plated steel with 430 stainless steel pin and rod
 - Stainless steel 316L

Advantage

- Invisible when the door is closed


Mounting

- Flush or surface mounting
- Right- or left-hand mounting
- Vertical or horizontal mounting

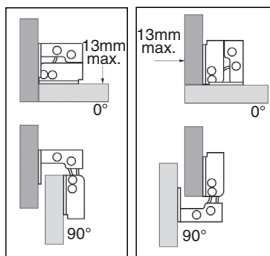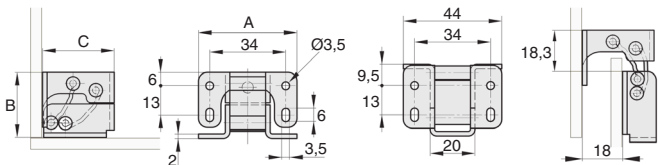

Hanging a built-in door

Hanging a surface mounted door

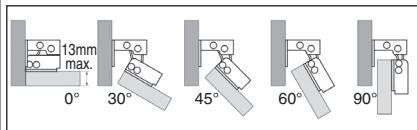

Example of hanging a built-in door

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Net	-5%	-10%	On request

Part number	Material	Finish	A	B	C	Weight (g)	Price each
CHINV-4429	Steel	Zinc-plated	44	29	32	64	18,51 €
CHINV-4429/SS	Stainless steel 316L	Natural	44	29	32	64	31,04 €

All dimensions in mm

Our other products



HDSS

Needle roller double universal joint - Stainless steel, Heavy duty



MFBC

Flexible Bellows coupling, Aluminium and Bronze - with clamping jaw



HTD14M_85

HTD Heavy duty timing pulley, HTD14 Steel



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane




HTD5M_15

HTD Heavy duty timing pulley, HTD5 Steel



BAC105

 Storage bin, 8mm



AC

Strike for toggle latch, 15mm



 
BPTRW

Cap for round tube to be welded, To be welded



METC

Flanged sintered bronze bush, Self-lubricating



TBV

Manual lifting tables, For vertical strokes -



FHCSS

Countersunk screw, Stainless steel A2 -



DB

Steel bevel gear, 2:1

Complementary products



CHINV

Invisible hinge, Invisible - 90° opening



CHA1056_U4

Screw-in hinge, Section 40X40