

# Steel or stainless steel invisible hinge

Sta

## CHINV For nested doors or surface mounted doors



- Invisible hinge with connecting rods
- 90° opening
- Material:
  - Zinc-plated steel with 430 stainless steel pin and rod
  - Stainless steel 316L raw

### Advantage


- Invisible when the door is closed

### Mounting



- Flush or surface mounting
- Right- or left-hand mounting
- Vertical or horizontal mounting

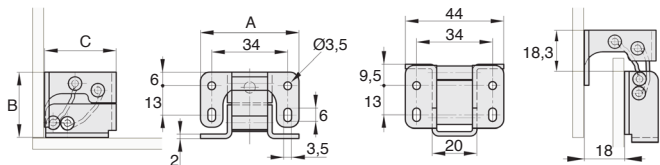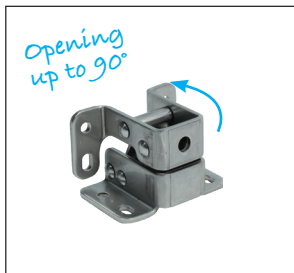

### Hanging a built-in door

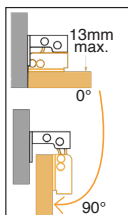

### Hanging a surface mounted door

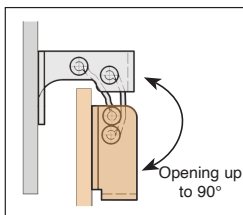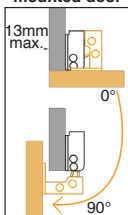

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. Net	-5%	-10%	-10%	On request

Part number	Material	A	B	C	Weight (g)	Stock*	Price each 1 to 5
CHINV-4429	Steel	44	29	32	64	✓	22,21 €
CHINV-4429/SS	Stainless steel 316L	44	29	32	64	-	31,04 €

\*Depending on availability - Dimensions in mm

# Steel or stainless steel invisible hinge

## CHINV For nested doors or surface mounted doors





- Concealed hinges (Medium size)
- 125° opening
- Material:
  - Steel zinc plated or 316L stainless steel raw
  - Links in aluminium
  - Pin in zinc plated steel or in 304Cu stainless steel

### Advantage

- Invisible when the door is closed

### Assembly

- For nested doors or surface mounted doors
- LH or RH options
- For horizontal or vertical applications.
- Opening angle differs according to door thickness:
  - For thickness up to 10 mm: opening angle of 125°
  - 15 mm thickness: opening angle of 115°
  - 20 mm thickness: opening angle of 108°

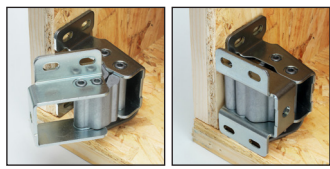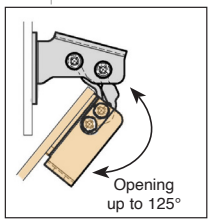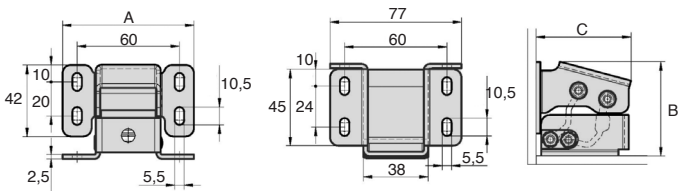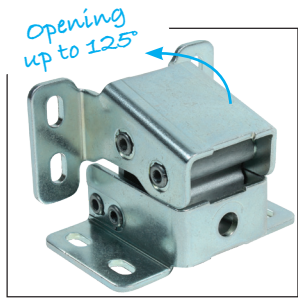

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Material	A	B	C	Weight (g)	Price each	
						Stock*	1 to 5
CHINV-7755	Steel	77	55,2	54,0	250	-	18,38 €
CHINV-7755/SS	Stainless steel	77	55,2	54,0	250	-	32,93 €

\*Depending on availability - Dimensions in mm

## Our other products



AT10-32ECO

AT type timing pulley,  
Economy range -  
AT10 aluminium



RCC\_RCX

Spherical tilt washer -  
DIN6319, convex



AT10-25ECO

AT type timing pulley,  
Economy range -  
AT10 aluminium



PT821

Drive sprocket for slat  
top chain, Ranges 821  
and 805



UGH25

H Type Guide units,  
For Ø25 actuators



DOMI120

Accessories, Plate



GMK17\_BR

Clamp for guiding  
profile, Rounded only  
- double



CHA1056-U4

Screwed hinge, 180°



 
HTD5M\_15

HTD Heavy duty  
timing pulley, HTD5  
Steel



SBF

Sealed flange bearing  
unit for Food Industry,  
cover



M1

Worm and wheel set,  
Machined plastic  
(delrin)



PRF\_BR

Clamp for aluminium  
profile, Clamp for  
profile

## Complementary products



CHINV

Invisible hinge,  
Invisible - 90° opening



CHINV2

Invisible hinge,  
Invisible - Opening up  
to 125°



CHA1056\_U4

Screw-in hinge,  
Section 40X40