




Worm and wheel gearbox

Torque up to 298 Nm


CHM75

- Ratios from 7.5:1 to 100:1
- With B14 flange acc IEC80 for ratios 7.5:1 to 15:1
- With B14 mounting flange acc IEC71 for ratios 20:1 to 30:1
- Output backlash: N/A
- Max. input speed: 2,800 rpm
- Max. output speed: see CHMR75
- Materials:
 - Casing: aluminium
 - Screws: treated steel 20CR
 - Wheel: bronze CuSn12 (cast iron hub G500)
- Lubrication: synthetic oil ISO VG320
- Weight: 8.5 kg

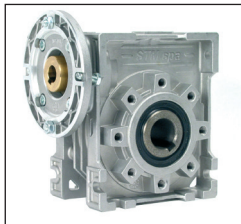

Accessories

- Output shaft **CHM75-X** or **CHM75-DX**
- Torque arm **CHM75-BR**

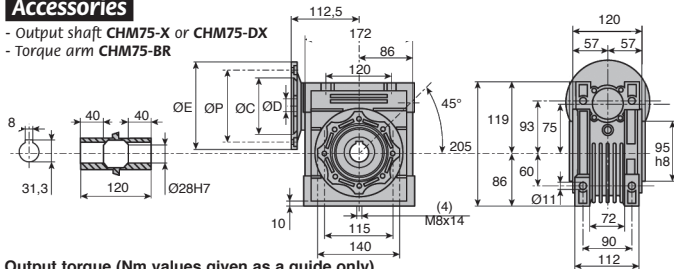

Output torque (Nm values given as a guide only)

Ratio	7.5:1	10:1	15:1	20:1	25:1	30:1	40:1	50:1	60:1	80:1	100:1
INPUT	2800	129	144	148	158	148	119	168	146	144	129
SPEED (rpm)	1400	184	194	198	209	198	159	228	209	198	178
	900	214	228	234	234	214	174	258	218	209	186
	500	258	268	278	284	254	198	298	248	238	208

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-20%	-20%	On request

Part number	Reduction ratio	Input flange	ØD	ØC	ØP	ØE	Self locking output	Stock*	Price each
								✓	€
CHM75-7	7.5:1	90B14	24	95	115	140	no	-	390,49 €
CHM75-10	10:1	90B14	24	95	115	140	no	-	390,49 €
CHM75-15	15:1	90B14	24	95	115	140	no	-	390,49 €
CHM75-20	20:1	80B14	19	80	100	120	no	-	390,49 €
CHM75-25	25:1	80B14	19	80	100	120	no	✓	390,49 €
CHM75-30	30:1	80B14	19	80	100	120	no	-	390,49 €
CHM75-40	40:1	80B14	19	80	100	120	no	-	390,49 €
CHM75-50	50:1	80B14	19	80	100	120	not defined	✓	390,49 €
CHM75-60	60:1	80B14	19	80	100	120	not defined	-	390,49 €
CHM75-80	80:1	80B14	19	80	100	120	not defined	✓	390,49 €
CHM75-100	100:1	80B14	19	80	100	120	yes	✓	390,49 €

*Depending on availability - Dimensions in mm

Our other products



 
SRG

Adjustable latch clamp with strike plate, Stroke from 77,3mm to 83mm



WING

Manually tightened wing nut, Stainless steel DIN 314/315



H0

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



LRRss

Latch, Spring loaded latch - stainless steel



DZY

Cylindrical stop, Steel



V3RA_PT

3-spoked handwheel with handle, Polyamide



T10-BAR

T type tooth bar stock, T10



SSB

Stainless steel bevel gear, 1:1



HG8-ECO

Eco range Spur gear, Steel C45



VEL

Self-gripping cable strip, electric and



PSG125

Spur gear - precision range, Pre-hardened



BUT

Panel stop, Panel stop

Complementary products



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



CHMBR

Reaction arm, CHM and CHMR gear reducers reaction arm



PF70

Worm and wheel gear reducer, up to 164 Nm