




Worm and wheel gearbox

Torque up to 298 Nm


CHM75

- Ratios from 7.5:1 to 100:1
- With B14 flange acc IEC80 for ratios 7.5:1 to 15:1
- With B14 mounting flange acc IEC71 for ratios 20:1 to 30:1
- Output backlash: N/A
- Max. input speed: 2,800 rpm
- Max. output speed: see CHMR75
- Materials:
 - Casing: aluminium
 - Screws: treated steel 20CR
 - Wheel: bronze CuSn12 (cast iron hub G500)
- Lubrication: synthetic oil ISO VG320
- Weight: 8.5 kg

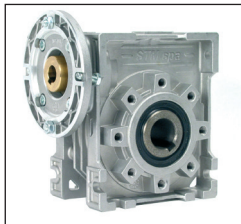

Accessories

- Output shaft **CHM75-X** or **CHM75-DX**
- Torque arm **CHM75-BR**

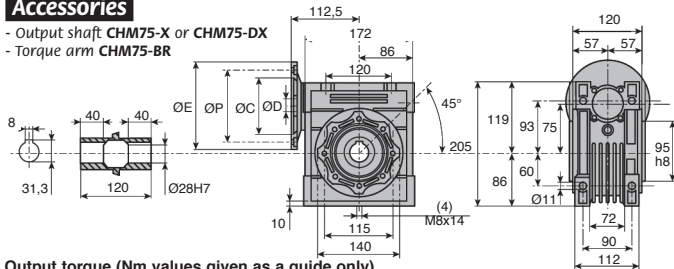

Output torque (Nm values given as a guide only)

Ratio	7.5:1	10:1	15:1	20:1	25:1	30:1	40:1	50:1	60:1	80:1	100:1
INPUT	2800	129	144	148	158	148	119	168	146	144	129
SPEED (rpm)	1400	184	194	198	209	198	159	228	209	198	188
	900	214	228	234	234	214	174	258	218	209	198
	500	258	268	278	284	254	198	298	248	238	214

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-20%	-20%	On request

Part number	Reduction ratio	Input flange	ØD	ØC	ØP	ØE	Self locking output	Stock*	Price each
								✓	€
CHM75-7	7.5:1	90B14	24	95	115	140	no	-	390,49 €
CHM75-10	10:1	90B14	24	95	115	140	no	-	390,49 €
CHM75-15	15:1	90B14	24	95	115	140	no	-	390,49 €
CHM75-20	20:1	80B14	19	80	100	120	no	-	390,49 €
CHM75-25	25:1	80B14	19	80	100	120	no	✓	390,49 €
CHM75-30	30:1	80B14	19	80	100	120	no	-	390,49 €
CHM75-40	40:1	80B14	19	80	100	120	no	-	390,49 €
CHM75-50	50:1	80B14	19	80	100	120	not defined	✓	390,49 €
CHM75-60	60:1	80B14	19	80	100	120	not defined	-	390,49 €
CHM75-80	80:1	80B14	19	80	100	120	not defined	✓	390,49 €
CHM75-100	100:1	80B14	19	80	100	120	yes	✓	390,49 €

*Depending on availability - Dimensions in mm

Our other products



LVT

Miniature motorised actuator 4A, 4 ampers



PSG05

Spur gear - precision range, Pre-hardened Steel 35NCD6



PSPT

Flexible tube handle, PVC



BCA

Steel splined collar, Steel




PO

Pull handle - Multi-sector, Tapped recessed insert



CQA30

 Adjustment slide-system miniature, 30



CF

Cam follower, Standard - steel



PLM-20SC

Threaded cylindrical magnet, With threaded hole



TCC_SS

Stainless steel rigging screw (hook/hook),



MFB_MHB

Moulded plastic bevel gear (nylon), 4:1



GE1006

Elastic ringed latch, Hooks into a slot



BDP2R

Adjustable support arm, Increased grip

Complementary products



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



CHMBR

Reaction arm, CHM and CHMR gear reducers reaction arm



PF70

Worm and wheel gear reducer, up to 164 Nm