


# Single and double output shafts

For CHM and CHMR gear gearboxes **CHMX**  
**CHMDX**

- Mounts into the bores of the CHM and CHMR gear gearboxes
- Shaft steel C40

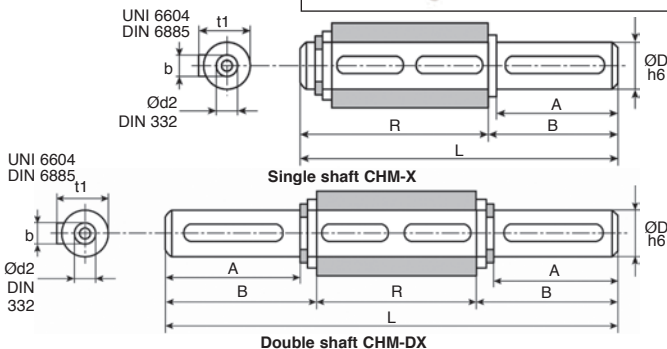

## DISCOUNTS <sup>A</sup>

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

## DISCOUNTS <sup>B</sup>

Qty	1+	2+	6+	15+
Disc.	List	-5%	-15%	On request

Part number	ØD h6	A	B	b	t1	R	L	Ød2	Weight (kg)	Stock*	Price each 1 to 5
<b>Single shaft</b>											
CHM30-X	14	30	32,5	5	16,0	69,5	102	M6x16	0,14	✓	<sup>A</sup> 14,23 €
CHM40-X	18	40	43,0	6	20,5	85,0	128	M6x16	0,27	✓	<sup>A</sup> 16,79 €
CHM50-X	25	50	53,5	8	28,0	99,5	153	M10x22	0,60	✓	<sup>A</sup> 19,31 €
CHM63-X	25	50	53,5	8	28,0	119,5	173	M10x22	0,67	✓	<sup>A</sup> 21,49 €
CHM75-X	28	60	63,5	8	31,0	128,5	192	M10x22	0,94	✓	<sup>A</sup> 23,99 €
CHM90-X	35	80	84,5	10	38,0	149,5	234	M12x28	1,79	✓	<sup>B</sup> 35,73 €
CHM110-X	42	80	84,5	12	45,0	164,5	249	M16x35	2,70	-	<sup>B</sup> 40,43 €
<b>Double shaft</b>											
CHM30-DX	14	30	32,5	5	16,0	63,0	128	M6x16	0,16	✓	<sup>A</sup> 19,31 €
CHM40-DX	18	40	43,0	6	20,5	78,0	164	M6x16	0,34	✓	<sup>A</sup> 21,49 €
CHM50-DX	25	50	53,5	8	28,0	92,0	199	M10x22	0,75	✓	<sup>A</sup> 23,99 €
CHM63-DX	25	50	53,5	8	28,0	112,0	219	M10x22	0,84	-	<sup>A</sup> 26,17 €
CHM75-DX	28	60	63,5	8	31,0	120,0	247	M10x22	1,20	✓	<sup>B</sup> 28,49 €
CHM90-DX	35	80	84,5	10	38,0	140,0	309	M12x28	2,50	✓	<sup>B</sup> 42,06 €
CHM110-DX	42	80	84,5	12	45,0	155,0	324	M16x35	3,44	-	<sup>B</sup> 50,03 €

\*Depending on availability - Dimensions in mm

## Our other products



BCTH

Mushroom headed button Hygienic Usit®, With female thread and high ...



RMSA

Adjustable shock-absorber, Adjustable



PDR-RD

Mounting feet with integrated castors, Offset castor



ZBconique

Machined plastic bevel gear, 1:1



AC

Strike for toggle latch, 15mm



PW\_PWG2

Wheel - precision range, Bronze



BAG

Steel Clamping collar, Steel



HRV

V-rail guidance Simple Select® system, Rail with carriage



CHAK

Hi-Klik™ indent hinge, Hi-Klik™ - Detent hinge



PENC

Recessed handle, clip-in



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78

## Complementary products



CHMR30

Worm and wheel gear reducer, up to 28 Nm



CHM30

Worm and wheel gear reducer, up to 28 Nm