

Straight long link chain

Ste

CHN Conforms to NFE26020 and DIN5685C

 


- Galvanised steel chain, supplied by the box

Applications

- Rigging, safety barriers, signage

Info.

- Under no circumstances should this type of chain be used for lifting

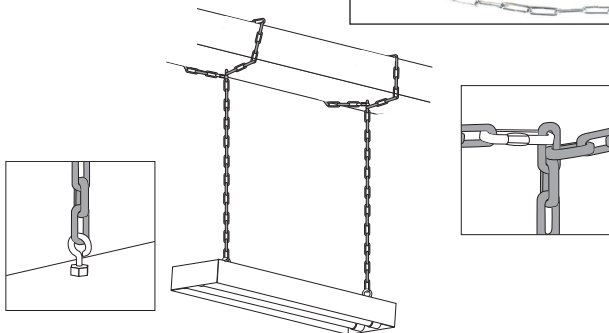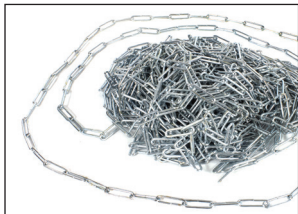

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-10%	-15%	On request

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each 1 to 2
CHN-2/B	2,0	22	4	25	25	1,56	✓	24,84 €
CHN-2.5/B	2,5	24	5	40	25	2,53	-	28,40 €
CHN-3/B	3,0	26	6	60	25	3,70	✓	35,02 €
CHN-3.5/B	3,5	28	7	75	25	5,30	-	45,11 €
CHN-4/B	4,0	32	8	100	25	6,70	✓	51,82 €
CHN-4.5/B	4,5	34	9	125	25	8,90	✓	63,26 €
CHN-5/B	5,0	35	10	155	25	10,00	✓	69,13 €
CHN-6/B	6,0	42	12	230	25	15,70	-	99,57 €
CHN-7/B	7,0	49	14	300	25	21,40	-	135,89 €
CHN-8/B	8,0	52	16	400	10	11,60	-	70,11 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Sta Straight long link stainless steel chain

Conforms to NFE26020 and DIN5685C CHNss


- Stainless steel chain, supplied by the box

Applications

- Rigging, safety barriers, signage

Info.

- Under no circumstances should this type of chain be used for lifting

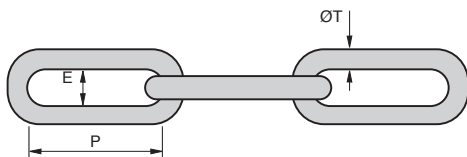


DISCOUNTS

Qty	1+	2+	4+
Disc. List	-15%	On request	

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each
CHN-2/SS/B	2,0	22	4	25	25	1,49	✓	81,06 €
CHN-2.5/SS/B	2,5	24	5	40	25	2,54	✓	119,42 €
CHN-3/SS/B	3,0	26	6	60	25	3,74	✓	171,46 €
CHN-4/SS/B	4,0	32	8	100	25	6,83	✓	286,95 €
CHN-5/SS/B	5,0	35	10	155	25	10,64	✓	447,65 €
CHN-6/SS/B	6,0	42	12	230	25	15,62	-	654,70 €
CHN-8/SS/B	8,0	52	16	400	10	11,28	-	447,65 €

*Depending on availability - Dimensions in mm

Our other products

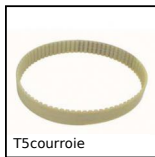

T5courroie

T type timing belt, T5
Steel cored
polyurethane



HTD8M_20

HTD Heavy duty
timing pulley, HTD8
Steel



BHC

Socket head button
screw, Stainless steel
A2



J64

Spur gear coaxial
gearbox, from 0.57 to
2.25 Nm - In-line



PR882

Idler sprocket for slat
top chain, Range 882




BPHT

Ball transfer unit bolt
fitting, Heavy




CHAE6555

 Decorative screwed
hinge, Aluminium



TR

 Spur round rack,
Stainless steel -
module 0,25-1,5



GPLac

Brush, steel



UGAC_UGET

Connection for
threaded actuator
rod, Connection for



PRF_CHA

Hinge for aluminium
profile, Surface
mounting hinge



T2

T type timing belt,
T2.5 Steel cored
polyurethane

Complementary products



MRA

Quick link, Steel



MRAeco

Low cost quick link,
Steel



WSS

Symmetrical S shaped
hook, Steel



CHNrb

Warning chain with
red and white links,
Steel