

# Straight long link chain

Ste

CHN Conforms to NFE26020 and DIN5685C

 


- Galvanised steel chain, supplied by the box

## Applications

- Rigging, safety barriers, signage

## Info.

- Under no circumstances should this type of chain be used for lifting

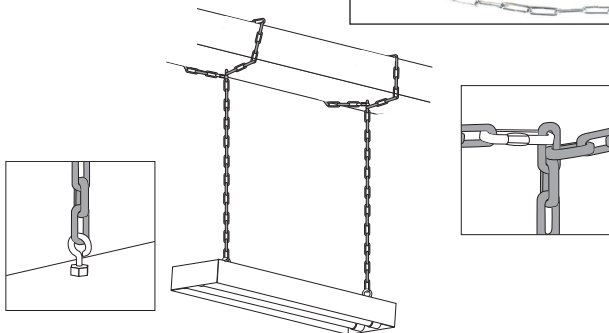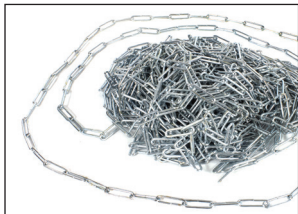

## DISCOUNTS

| Qty   | 1+   | 3+   | 5+   | 10+        |
|-------|------|------|------|------------|
| Disc. | List | -10% | -15% | On request |

| Part number | Chain<br>ØT | P  | E  | Max carrying<br>load (kg) | Length / Box<br>(m) | Weight / Box<br>(kg) | Stock* | Price each<br>1 to 2 |
|-------------|-------------|----|----|---------------------------|---------------------|----------------------|--------|----------------------|
| CHN-2/B     | 2,0         | 22 | 4  | 25                        | 25                  | 1,56                 | ✓      | 24,84 €              |
| CHN-2.5/B   | 2,5         | 24 | 5  | 40                        | 25                  | 2,53                 | -      | 28,40 €              |
| CHN-3/B     | 3,0         | 26 | 6  | 60                        | 25                  | 3,70                 | ✓      | 35,02 €              |
| CHN-3.5/B   | 3,5         | 28 | 7  | 75                        | 25                  | 5,30                 | ✓      | 45,11 €              |
| CHN-4/B     | 4,0         | 32 | 8  | 100                       | 25                  | 6,70                 | ✓      | 51,82 €              |
| CHN-4.5/B   | 4,5         | 34 | 9  | 125                       | 25                  | 8,90                 | ✓      | 63,26 €              |
| CHN-5/B     | 5,0         | 35 | 10 | 155                       | 25                  | 10,00                | ✓      | 69,13 €              |
| CHN-6/B     | 6,0         | 42 | 12 | 230                       | 25                  | 15,70                | -      | 99,57 €              |
| CHN-7/B     | 7,0         | 49 | 14 | 300                       | 25                  | 21,40                | -      | 135,89 €             |
| CHN-8/B     | 8,0         | 52 | 16 | 400                       | 10                  | 11,60                | -      | 70,11 €              |

\*Depending on availability - Dimensions in mm

# Stainless steel chain

Conforms to NFE26020 and DIN5685C CHNss


- Stainless steel chain, supplied by the box

## Applications

- Rigging, safety barriers, signage

## Info.

- Under no circumstances should this type of chain be used for lifting

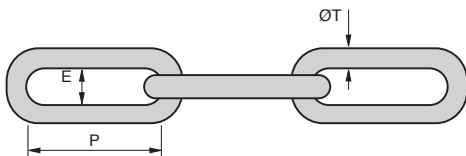

## DISCOUNTS

|            |      |            |    |
|------------|------|------------|----|
| Qty        | 1+   | 2+         | 4+ |
| Disc. List | -15% | On request |    |

| Part number  | Chain ØT | P  | E  | Max carrying load (kg) | Length / Box (m) | Weight / Box (kg) | Stock* | Price each |
|--------------|----------|----|----|------------------------|------------------|-------------------|--------|------------|
| CHN-2/SS/B   | 2,0      | 22 | 4  | 25                     | 25               | 1,49              | ✓      | 81,06 €    |
| CHN-2.5/SS/B | 2,5      | 24 | 5  | 40                     | 25               | 2,54              | ✓      | 119,42 €   |
| CHN-3/SS/B   | 3,0      | 26 | 6  | 60                     | 25               | 3,74              | ✓      | 171,46 €   |
| CHN-4/SS/B   | 4,0      | 32 | 8  | 100                    | 25               | 6,83              | ✓      | 286,95 €   |
| CHN-5/SS/B   | 5,0      | 35 | 10 | 155                    | 25               | 10,64             | ✓      | 447,65 €   |
| CHN-6/SS/B   | 6,0      | 42 | 12 | 230                    | 25               | 15,62             | -      | 654,70 €   |
| CHN-8/SS/B   | 8,0      | 52 | 16 | 400                    | 10               | 11,28             | -      | 447,65 €   |

\*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB  
04/2020

**HPC**

## Our other products



G3-ECO

Eco range Spur gear,  
Steel C45



EBC

Cap nut Hygienic  
Design®, Compact



CLB\_M

Die cast zinc clamping  
lever - female, Zamak



M2

Worm and wheel set,  
Bronze



NSR

Adjustable clamp,  
Adjustable



NDS20

Double cross clamp,  
Crossed



CHM30

Worm and wheel gear  
reducer, up to 28 Nm



BVR

Adjustable screw stop,  
Steel



VTHbr

Hexagonal headed  
screw VTH - DIN933,  
Brass



E50

Right angle helical  
reducers, from 3 to 41  
Nm



PTKss

Foot for the food  
industry, Stainless  
steel - 3-A standard



CM\_CO

Tools Hygienic Usit®  
and Hygienic  
Design®, Protective  
inserts for ...

## Complementary products



MRASeco

Low cost stainless  
steel quick link,  
Stainless steel



MRA\_SS

Stainless steel Quick  
link, Stainless steel



FCHN\_CHNSS

Straight long link  
chain, Galvanised  
steel



PPCss

Pad eye on mounting  
plate squarred,  
Stainless steel