

# Straight long link chain

Ste

CHN Conforms to NFE26020 and DIN5685C

 


- Galvanised steel chain, supplied by the box

## Applications

- Rigging, safety barriers, signage

## Info.

- Under no circumstances should this type of chain be used for lifting

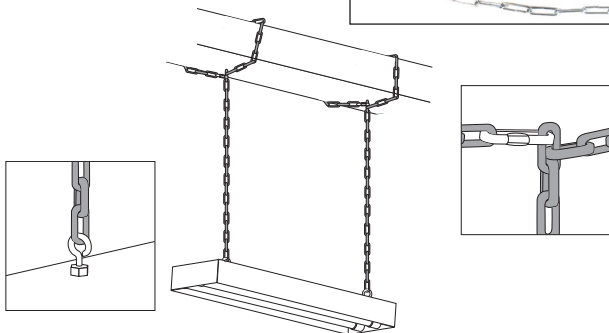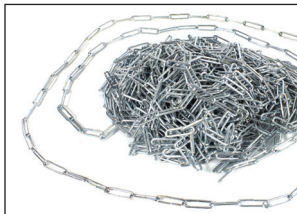

## DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-10%	-15%	On request

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each 1 to 2
CHN-2/B	2,0	22	4	25	25	1,56	✓	24,84 €
CHN-2.5/B	2,5	24	5	40	25	2,53	-	28,40 €
CHN-3/B	3,0	26	6	60	25	3,70	✓	35,02 €
CHN-3.5/B	3,5	28	7	75	25	5,30	-	45,11 €
CHN-4/B	4,0	32	8	100	25	6,70	✓	51,82 €
CHN-4.5/B	4,5	34	9	125	25	8,90	✓	63,26 €
CHN-5/B	5,0	35	10	155	25	10,00	✓	69,13 €
CHN-6/B	6,0	42	12	230	25	15,70	-	99,57 €
CHN-7/B	7,0	49	14	300	25	21,40	-	135,89 €
CHN-8/B	8,0	52	16	400	10	11,60	-	70,11 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

# Sta Straight long link stainless steel chain

Conforms to NFE26020 and DIN5685C CHNss


- Stainless steel chain, supplied by the box

## Applications

- Rigging, safety barriers, signage

## Info.

- Under no circumstances should this type of chain be used for lifting

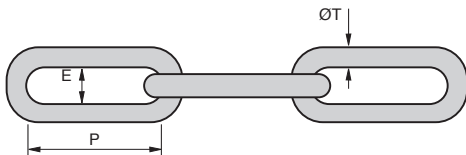

## DISCOUNTS

Qty	1+	2+	4+
Disc. List	-15%	On request	


Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each
CHN-2/SS/B	2,0	22	4	25	25	1,49	✓	81,06 €
CHN-2.5/SS/B	2,5	24	5	40	25	2,54	✓	119,42 €
CHN-3/SS/B	3,0	26	6	60	25	3,74	✓	171,46 €
CHN-4/SS/B	4,0	32	8	100	25	6,83	✓	286,95 €
CHN-5/SS/B	5,0	35	10	155	25	10,64	✓	447,65 €
CHN-6/SS/B	6,0	42	12	230	25	15,62	-	654,70 €
CHN-8/SS/B	8,0	52	16	400	10	11,28	-	447,65 €

\*Depending on availability - Dimensions in mm

## Our other products



 PC575K  
Chain sprocket with  
hardened teeth,  
19.05mm (DIN12B-1)



GLT3-76  
Telescopic drawer,



ES  
Simple support base  
(bipod), Plastic



 
RPP  
Connecting plate for  
RPP type timing belts,  
RPP8



TOL  
Swivel head, Long



SFWR  
End support, Surface  
mounting



GE  
Toggle latches,  
Standard



ERF  
Quick fitting threaded  
cable terminal, Cable  
terminal with  
threaded ...




DOMI30  
Accessories, Turntable



SUPss  
Self-centering  
clamping hub



 SVR15  
Screwjack with  
travelling nut, with



PF30NM  
Worm and wheel gear  
reducer, up to 8.8 Nm

## Complementary products



MRA  
Quick link, Steel



MRAeco  
Low cost quick link,  
Steel



WSS  
Symmetrical S shaped  
hook, Steel



CHNrb  
Warning chain with  
red and white links,  
Steel