

Straight long link chain

Ste

CHN Conforms to NFE26020 and DIN5685C

 


- Galvanised steel chain, supplied by the box

Applications

- Rigging, safety barriers, signage

Info.

- Under no circumstances should this type of chain be used for lifting

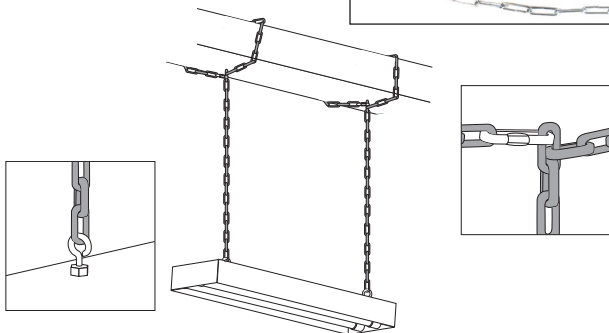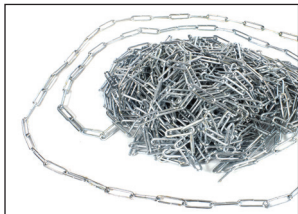

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-10%	-15%	On request

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each 1 to 2
CHN-2/B	2,0	22	4	25	25	1,56	✓	24,84 €
CHN-2.5/B	2,5	24	5	40	25	2,53	-	28,40 €
CHN-3/B	3,0	26	6	60	25	3,70	✓	35,02 €
CHN-3.5/B	3,5	28	7	75	25	5,30	-	45,11 €
CHN-4/B	4,0	32	8	100	25	6,70	✓	51,82 €
CHN-4.5/B	4,5	34	9	125	25	8,90	✓	63,26 €
CHN-5/B	5,0	35	10	155	25	10,00	✓	69,13 €
CHN-6/B	6,0	42	12	230	25	15,70	-	99,57 €
CHN-7/B	7,0	49	14	300	25	21,40	-	135,89 €
CHN-8/B	8,0	52	16	400	10	11,60	-	70,11 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Stainless steel chain

Conforms to NFE26020 and DIN5685C CHNss


- Stainless steel chain, supplied by the box

Applications

- Rigging, safety barriers, signage

Info.

- Under no circumstances should this type of chain be used for lifting

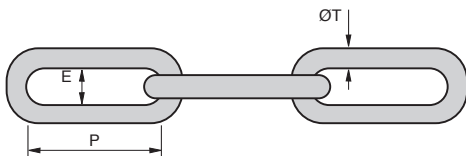

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-15%	On request	

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each
CHN-2/SS/B	2,0	22	4	25	25	1,49	✓	81,06 €
CHN-2.5/SS/B	2,5	24	5	40	25	2,54	✓	119,42 €
CHN-3/SS/B	3,0	26	6	60	25	3,74	✓	171,46 €
CHN-4/SS/B	4,0	32	8	100	25	6,83	✓	286,95 €
CHN-5/SS/B	5,0	35	10	155	25	10,64	✓	447,65 €
CHN-6/SS/B	6,0	42	12	230	25	15,62	-	654,70 €
CHN-8/SS/B	8,0	52	16	400	10	11,28	-	447,65 €

*Depending on availability - Dimensions in mm

Our other products



ADL_F

Female eye bolt conforms to DIN582, Stainless steel




E20

Right angle helical reducers, from 0.60 to 3.84 Nm



S_ZZ

Deep groove ball bearing, Stainless steel

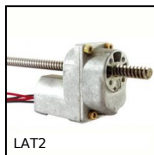

LAT2

2A motorised linear actuator, 2 amperes



BHC

Socket head button screw, Stainless steel A2



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



HK

Manual locking clamp, Manual locking clamp LWH



SLBW

Indexing plunger, weldable, Weldable -



PCS8ECO

Chain sprocket - steel, 8mm (DIN 05B-1)



VAP

Magnetic stud with central hole, With



NTM

Nylon tipped set screw, Nylon-point

Complementary products



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel




WSS

Symmetrical S shaped hook, Steel



MRAeco

Low cost quick link, Steel

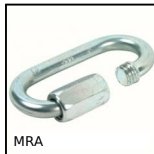

MRA

Quick link, Steel