

Straight long link chain

Ste

CHN Conforms to NFE26020 and DIN5685C

 


- Galvanised steel chain, supplied by the box

Applications

- Rigging, safety barriers, signage

Info.

- Under no circumstances should this type of chain be used for lifting

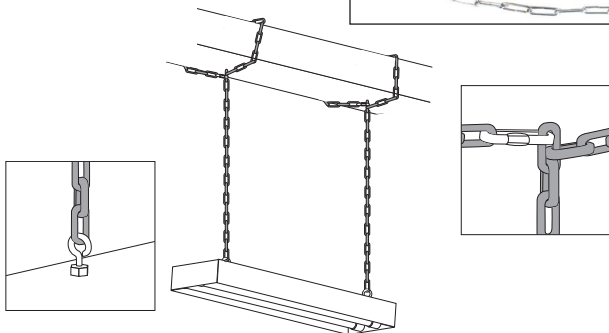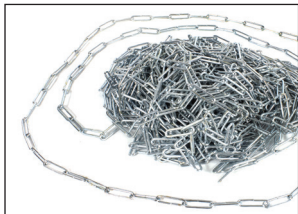

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-10%	-15%	On request

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each 1 to 2
CHN-2/B	2,0	22	4	25	25	1,56	✓	24,84 €
CHN-2.5/B	2,5	24	5	40	25	2,53	-	28,40 €
CHN-3/B	3,0	26	6	60	25	3,70	✓	35,02 €
CHN-3.5/B	3,5	28	7	75	25	5,30	-	45,11 €
CHN-4/B	4,0	32	8	100	25	6,70	✓	51,82 €
CHN-4.5/B	4,5	34	9	125	25	8,90	✓	63,26 €
CHN-5/B	5,0	35	10	155	25	10,00	✓	69,13 €
CHN-6/B	6,0	42	12	230	25	15,70	-	99,57 €
CHN-7/B	7,0	49	14	300	25	21,40	-	135,89 €
CHN-8/B	8,0	52	16	400	10	11,60	-	70,11 €

*Depending on availability - Dimensions in mm

Stainless steel chain

Conforms to NFE26020 and DIN5685C CHNss


- Stainless steel chain, supplied by the box

Applications

- Rigging, safety barriers, signage

Info.

- Under no circumstances should this type of chain be used for lifting

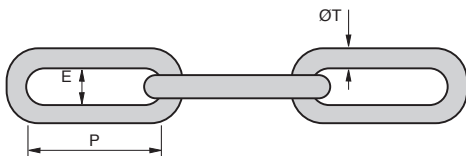

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-15%	On request	

Part number	Chain ØT	P	E	Max carrying load (kg)	Length / Box (m)	Weight / Box (kg)	Stock*	Price each
CHN-2/SS/B	2,0	22	4	25	25	1,49	✓	81,06 €
CHN-2.5/SS/B	2,5	24	5	40	25	2,54	✓	119,42 €
CHN-3/SS/B	3,0	26	6	60	25	3,74	✓	171,46 €
CHN-4/SS/B	4,0	32	8	100	25	6,83	✓	286,95 €
CHN-5/SS/B	5,0	35	10	155	25	10,64	✓	447,65 €
CHN-6/SS/B	6,0	42	12	230	25	15,62	-	654,70 €
CHN-8/SS/B	8,0	52	16	400	10	11,28	-	447,65 €

*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB
04/2020

HPC

Our other products



PWDL_PWGDL3

Worm - precision range, Peek



B3PAN

Panamech, Multi-Beam, Stainless steel - with clamping jaw



B_ECO

Bevel gear - Steel C43, 1:1



DBL880

Idler, Ranges 880 and 881



DFG

Suction cup, nitrile



712_001

Threaded spherical knob, spherical



 
MHMEP

Crank arm with rotating handle, Prebored



H0

90° crossed axis helical gear, Steel 20NCD2



RTN

Bowex®, toothed, Nylon



JSM

Bushing, Universal polymer



EIM

U bolt, Stainless steel



RCX-6

Spherical tilt washer - DIN 6319, convex

Complementary products



MRASeco

Quick link, Stainless steel



MRA_SS

Quick link, Stainless steel



PPC_{ss}

Pad eye on mounting plate, Stainless steel



WSS_{ss}

Symmetrical S shaped hook, Stainless steel