

# Warning chain

## CHN<sub>RB</sub>

With long red and white links


- Steel chain supplied by the box
- Red and white painted steel

### Applications

- Warning, signalling

### Info

- Not to be used for lifting applications

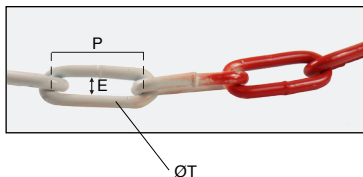

### DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%		On request

Part number	Link ØT	P	E	Typical working load (kg)	Length per box	Weight per box (kg)	Price each 1 to 2
CHN-5/RB/B	5	35	10	155	25	10,50	119,64 €

All dimensions in mm

**HPC**

WEB  
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



VLBS

Lifting ring, Folding -  
for welding



KBS\_UU

Linear bearing,  
Precision - stainless  
steel / -20° +140°



AC156-157

Catch plate for toggle  
latch, 25.5mm



WBGV

Lifting ring, Threaded



MATCD

Ground precision  
shaft, Pre-hardened  
steel (42CD4T) bar



LR

Bearing - accessories,  
Precision locknut



MSP38

Masterplate®  
glueable insert,  
Cylindrical Ø38 with  
tapped insert



FF10

Offset spur gear  
reducer, from 0.78 to  
3.70 Nm



DOMI120

DOMILINE -  
Accessories, XZ  
linking kit



MEB-ALI

Moulded plastic bevel  
gear (blue nylon), 1:1



HG8

Spur gear, Steel  
20NCND2



ZDB

Machined plastic  
bevel gear (delrin),  
2:1

## Complementary products



CHN\_CHNSS

Straight long link  
chain, Galvanised  
steel



MRA

Quick link, Steel



MAC

Carabiner, Steel



PPCcs

Pad eye on mounting  
plate, Stainless steel