

# Warning chain

## CHN<sub>RB</sub>

With long red and white links


- Steel chain supplied by the box
- Red and white painted steel

### Applications

- Warning, signalling

### Info

- Not to be used for lifting applications

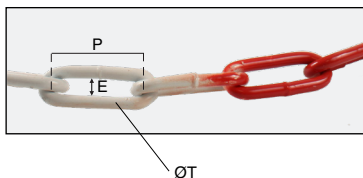

### DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%		On request

Part number	Link	Typical working load (kg)	Length per box	Weight per box (kg)	Price each 1 to 2		
	ØT	P	E				
CHN-5/RB/B	5	35	10	155	25	10,50	123,13 €

All dimensions in mm

**HPC**

WEB  
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



CHAL3

Piano hinge,  
Aluminium



RPCtc

Swivel castor with  
central hole, Steel -  
Polyamide - with  
double brake



TPEf

Castor for aluminium  
profile, Fixed



CLA

Clamping lever  
Hygienic Usit® -  
female, Stainless steel



NPTR\_M

Adjustable cross  
clamp, Adjustable



CHA\_GC\_9SS

Stainless steel garnet  
hinge, To be welded



Q4

Double row radial  
contact ball bearing,  
Radial contact - Steel



GET-AL

Jaw coupling,  
economy range,  
Aluminium



CFUURSS

Cam follower stainless  
steel, Standard -  
stainless steel



WW20

Drylin® W slide, slide  
assembly



PGNT

Thermoplastic T  
handle, With threaded  
spindle



PRF\_PGN

Door handle for  
aluminium profile,  
Handle with lock  
suitable

## Complementary products



CHN\_CHNSS

Straight long link  
chain, Galvanised  
steel



MRA

Quick link, Steel



MAC

Carabiner DIN5299  
steel, Steel



PPCss

Pad eye on mounting  
plate squarred,  
Stainless steel