


# Asynchronous **AC** motor 0.12 to 0.22kW

## CHT63

## Torque up to 1.77Nm

- 3 phase AC asynchronous motor
- 4 pole motor
- Supply frequency 50 Hz
- B14 mounting flange
- Insulation class F
- Ingress protection: IP55
- Bearings: ball bearings
- Can rotate in both directions
- Rotor: Squirrel cage

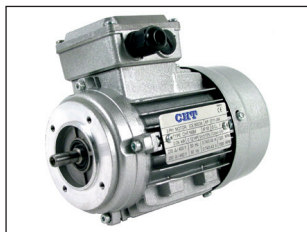


### Accessories

- Gearbox **CHM**

### Option

- Motor with B5 mounting flange

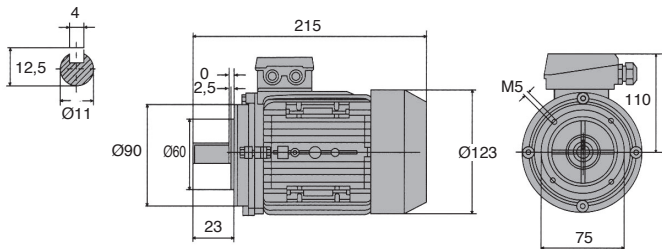

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	Power (kW)	Power supply (V)	Current at 400V (A)	Torque (Nm)	Efficiency	Power factor cos	Weight (kg)	Price each
CHT63A4-B14	0,12	230/400	0,47	0,86	57%	0,64	3,9	103,87 €
CHT63B4-B14	0,18	230/400	0,70	1,27	57%	0,65	4,5	108,90 €
CHT63C4-B14	0,22	230/400	0,92	1,77	59%	0,67	4,8	114,38 €

Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



GP75

Spring loaded toggle latch, Standard (GP75)



CHM63

Worm and wheel gear reducer, up to 196 Nm



WJUM10

Drylin® W bearing block, Slide



ZG2

Plastic spur gear, Machined plastic (delrin)



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



SUPCC

Self-centering clamping hub steel, With lock nut



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



FGWA

End support, With base



CHA38\_SS

Stainless steel face frame hinge, Surface mount



PDD

Actuating plunger, Non-rotating detector shaft



RFVbr

Stainless steel reaction arm, Reaction arm



PSG3

Spur gear - precision range, Case hardened steel 20NCD2

## Complementary products



CHM30

Worm and wheel gear reducer, up to 28 Nm



CHM40

Worm and wheel gear reducer, up to 57 Nm