

## CLAUSS

## Hygienic Usit®

### - Indexing lever with female thread and collar for a sealing washer

- EHEDG certification

- Material:

Stainless steel 1.4404 (316L)

Polished finish up to Ra<0.04

### Advantages


- Intended for use in hygienic environments. The completely sealed handle and a gasket prevent contamination inside the lever.
- In addition, the insert is fitted with a conical insert so that the screwed connection can be hygienically sealed to the sealing washer.
- The lever rotates freely when not in use.



### Accessory

- RDE sealing washers (cf. pages 37 à 39)

Apply pressure to engage the lever (safety feature)

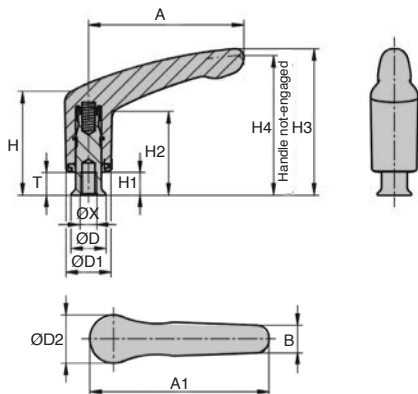

### DISCOUNTS

Qty	1+	5+	10+
Disc. Net	-5%		On request

Part N°	ØX	T	ØD	ØD1	ØD2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each
															1 to 4
CLA03M8/HUSS	M8	12	18	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	68,92 €
CLA03M10/HUSS	M10	15	22,3	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	69,96 €

All dimensions in mm

## Our other products



CHA1056\_U4

Screw-in hinge,  
Section 40X40



RAGFLOW

Flowlay2® roller track,  
Roller track



PW\_PWG15

Worm - precision  
range, Stainless steel



HBM

Adjustment bushing  
for half-rail guide,  
Adjustment bushing



LOQ

Manual lock, Manual  
latch



PW\_PWG1

Worm - precision  
range, Stainless steel



CHAL3

Piano hinge,  
Aluminium



PLM-SC

Magnetic stud with  
threaded hole, With  
threaded hole



HTD8M\_30

HTD Heavy duty  
timing pulley, HTD8  
Cast



NT61

Spur gear coaxial  
gearbox, from 5 to 14  
Nm - Inline



EMS

 
Stainless steel knurled  
thumb nut, Knurled



PRF\_PA

Angle plate for  
aluminium profile,  
Adjustable plate

## Complementary products



RDE-W

Sealing washer  
Hygienic Usit®,  
Stainless steel - White  
EPDM



RDE-B

Sealing washer  
Hygienic Usit®,  
Stainless steel - Blue  
EPDM



CLAT

Clamping lever  
Hygienic Usit® -  
male, Stainless steel