

CLass

With threaded insert

- Stainless steel indexing handle with threaded insert

- Materials:

Precision cast handle: stainless steel 304


Other components: stainless steel 303

- Finish:

Handle: electrolytically polished stainless steel

Other components: polished stainless steel

stainless steel

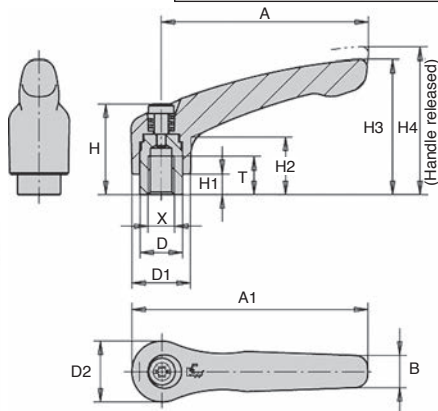

Pull the handle
to unlock



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread		X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each	
																	Stock*	1 to 5
CLA01M5/SS	M5	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	✓	21,06 €		
CLA01M6/SS	M6	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	-	21,06 €		
CLA02M6/SS	M6	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	✓	28,38 €		
CLA02M8/SS	M8	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	✓	28,38 €		
CLA03M8/SS	M8	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	✓	34,19 €		
CLA03M10/SS	M10	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	✓	34,19 €		
CLA04M10/SS	M10	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	✓	40,03 €		
CLA04M12/SS	M12	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	✓	40,03 €		

*Depending on availability - Dimensions in mm

- Stainless steel indexing handle with threaded shaft

- Materials:



Precision cast handle: stainless steel 304

Other components: stainless steel 303

- Finish:

Handle: electrolytically polished stainless steel

Other components: polished stainless steel

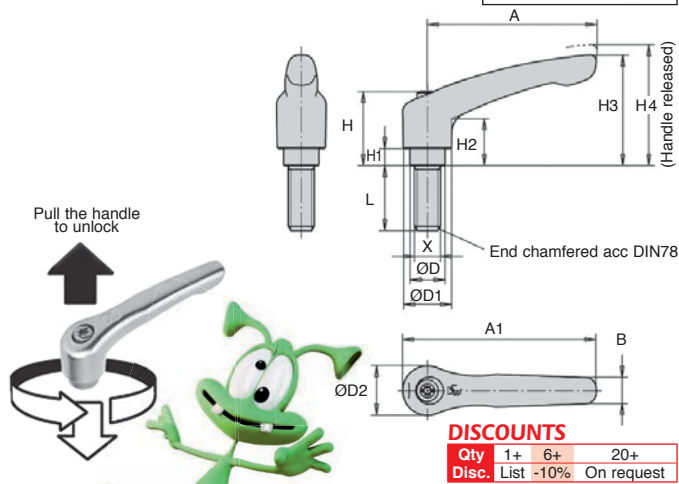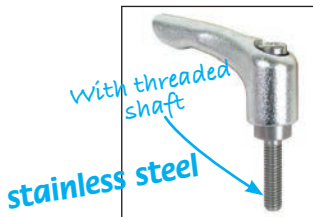

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Thread length L	Price each
CLA01T5/SS	M5	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	20	✓	21,67 €
CLA01T6/SS	M6	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	30	✓	21,67 €
CLA02T6/SS	M6	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓	30,12 €
CLA02T8/SS	M8	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓	30,12 €
CLA02T10/SS	M10	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓	30,12 €
CLA03T8/SS	M8	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	50	✓	36,16 €
CLA03T10/SS	M10	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	50	✓	36,16 €
CLA04T12/SS	M12	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	50	✓	42,45 €

*Depending on availability - Dimensions in mm

Our other products



EPRC

High helix leadscrew,
Cylindrical nut - up to
40mm per rotation



BLHM70

Right angled gearbox,
up to 128 Nm



NPR

Reflector support,



NCT

Square tube
connector, Fixed
angle



DEP

Tools Hygienic Usit®
and Hygienic
Design®, Protective
insert for s...



ACLEPP

Right angled bracket
for aluminium profile,
8 holes




HTD8M_20

HTD Heavy duty
timing pulley, HTD8
Steel



CQA30

 Adjustment slide-
system miniature, 30



CHAGC-AL

Screw-in garnet
hinge, Screw-on



BTC

End cap for square
tube, Standard



ZHG5

Plastic spur gear,
Machined plastic
(delrin)



UCFL_SS

Stainless steel flanged
bearing, Stainless
steel

Complementary products



CLB_T

Die cast zinc clamping
lever - male, Zamak



PCLA_T

Technopolymer
clamping lever - male,
Plastic



CLB_M

Die cast zinc clamping
lever - female, Zamak



PCLA_M

Technopolymer
clamping lever -
female, Plastic