

Stainless steel indexing handle

Sta Stock

CLAss

With threaded insert


- Stainless steel indexing handle with threaded insert

- Materials:

Precision cast handle: stainless steel 304
Other components: stainless steel 303

- Finish:

Handle: electrolytically polished stainless steel
Other components: polished stainless steel

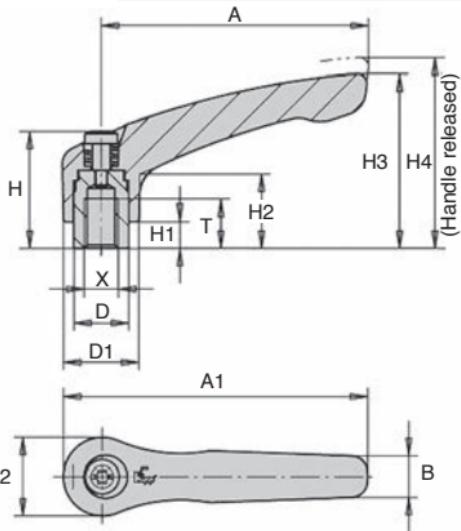

DISCOUNTS

Qty	1+	6+	20+
Disc. List	-10%	On request	

Part number	Thread										Nº of teeth	Price each 1 to 5		
	X	T	D	D1	D2	H	H1	H2	H3	H4				
CLA01M5/SS	M5	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16 ✓ 21,06 €
CLA01M6/SS	M6	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16 - 21,06 €
CLA02M6/SS	M6	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20 ✓ 28,38 €
CLA02M8/SS	M8	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20 ✓ 28,38 €
CLA03M8/SS	M8	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22 ✓ 34,19 €
CLA03M10/SS	M10	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22 ✓ 34,19 €
CLA04M10/SS	M10	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24 ✓ 40,03 €
CLA04M12/SS	M12	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24 ✓ 40,03 €

*Depending on availability - Dimensions in mm

- Stainless steel indexing handle with threaded shaft

- Materials:


Precision cast handle: stainless steel 304

Other components: stainless steel 303

- Finish:

Handle: electrolytically polished stainless steel

Other components: polished stainless steel

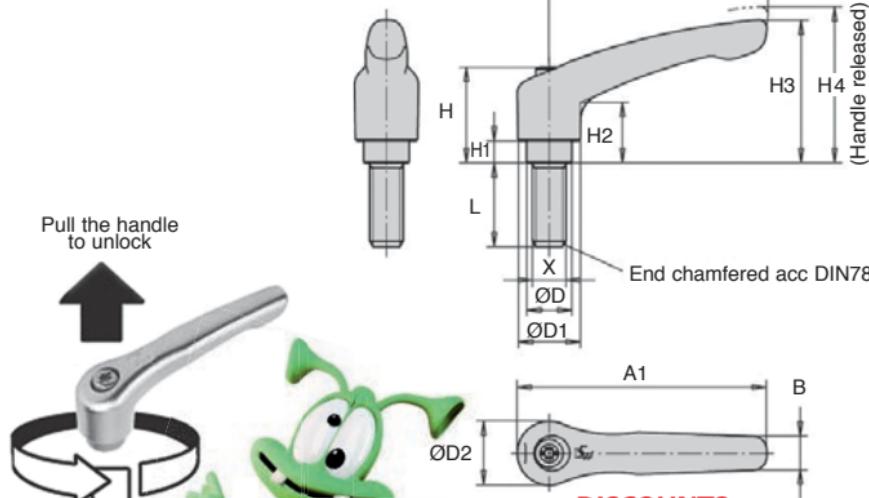

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	Thread							N° of teeth	Thread length L	Stock*	Price each 1 to 5
	X	D	D1	D2	H	H1	H2				
CLA01T5/SS	M5	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0
CLA01T6/SS	M6	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0
CLA02T6/SS	M6	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5
CLA02T8/SS	M8	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5
CLA02T10/SS	M10	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5
CLA03T8/SS	M8	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0
CLA03T10/SS	M10	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0
CLA04T12/SS	M12	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0

*Depending on availability - Dimensions in mm

Our other products



PSPT

Flexible tube handle,
PVC



ACLALF

Adjustable foot for
aluminium profile,
Ideal for workstations



GLB

Small 6 lobe female
handle,
Technopolymer -
Stainless steel



DB

Steel bevel gear, 2:1



H1

Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



BTC20_10

End cap for
rectangular tube,
Standard



CHAB

Hinge with stop,
Hinge



NRV

Orthogonal support
clamp, Orthogonal
support clamp



E20

Right angle helical
reducers, from 0.60 to



PCH

Knob for gripping,
Mushroom



GG3

Ground spur gear,
Heat treated steel



PAL

Self locking counter
nut, For axial locking

Complementary products



CLB_M

Die cast zinc clamping
lever - female, Zamak



PCLA_M

Technopolymer
clamping lever -
female, Plastic



CLASS

Stainless steel
indexing handle -
male, Stainless steel



PCLA_T

Technopolymer
clamping lever - male,
Plastic