

CLass

With threaded insert

- **Stainless steel indexing handle with threaded insert**

- **Materials:**

Precision cast handle: stainless steel 304

Other components: stainless steel 303


- **Finish:**

Handle: electrolytically polished stainless steel

Other components: polished stainless steel



stainless steel

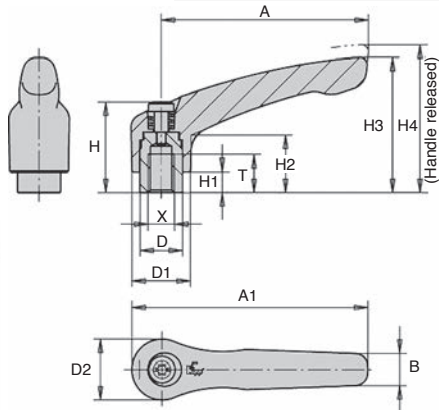

Pull the handle to unlock



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread		D	D1	D2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each	
	X	T													Stock*	1 to 5
CLA01M5/SS	M5	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	✓	21,06 €
CLA01M6/SS	M6	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	-	21,06 €
CLA02M6/SS	M6	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	✓	28,38 €
CLA02M8/SS	M8	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	✓	28,38 €
CLA03M8/SS	M8	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	✓	34,19 €
CLA03M10/SS	M10	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	✓	34,19 €
CLA04M10/SS	M10	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	✓	40,03 €
CLA04M12/SS	M12	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	✓	40,03 €

*Depending on availability - Dimensions in mm

- Stainless steel indexing handle with threaded shaft

- Materials:



Precision cast handle: stainless steel 304

Other components: stainless steel 303

- Finish:

Handle: electrolytically polished stainless steel

Other components: polished stainless steel

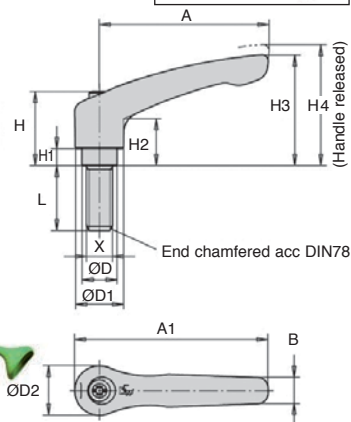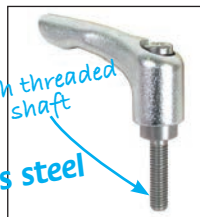

Pull the handle to unlock



End chamfered acc DIN78

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread				H	H1	H2	H3	H4	A	A1	B	N° of teeth	Thread length L	Price each
	X	D	D1	D2											
CLA01T5/SS	M5	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	20	✓ 21,67 €
CLA01T6/SS	M6	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	30	✓ 21,67 €
CLA02T6/SS	M6	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓ 30,12 €
CLA02T8/SS	M8	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓ 30,12 €
CLA02T10/SS	M10	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓ 30,12 €
CLA03T8/SS	M8	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	50	✓ 36,16 €
CLA03T10/SS	M10	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	50	✓ 36,16 €
CLA04T12/SS	M12	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	50	✓ 42,45 €

*Depending on availability - Dimensions in mm

Our other products



SLB
Indexing plunger,
steel class 5.8



MEP
Revolving handle for
handwheel, Fixed



P40
Worm and wheel gear
reducer, up to 18 Nm



VRC2
Retaining clamp, dual
sided, Dual sided




VTLF
3 lobed handle,
Polyamide - Brass




CHTRB
Single and dual
output gearboxes, Up
to 87,3 Nm



PSG2
Spur gear - precision
range, Case hardened
steel 20NCD2

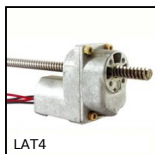

LAT4
4A motorised linear
actuator, 4 amperes

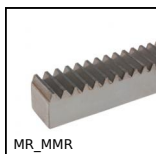

MR_MMR
Metric section rack,
Steel



CHB
Worm and wheel gear
reducer, up to 41 Nm



MEFC
Flanged sintered
ferrous bush, Self-
lubricating FP20



PSG1S
Spur gear - precision
range, Stainless steel
303

Complementary products



CLB_M
Die cast zinc clamping
lever - female, Zamak



PCLA_M
Technopolymer
clamping lever -
female, Plastic



CLASS
Stainless steel
indexing handle -
male, Stainless steel



PCLA_T
Technopolymer
clamping lever - male,
Plastic