

CLass

With threaded insert

- **Stainless steel indexing handle with threaded insert**

- **Materials:**

Precision cast handle: stainless steel 304

Other components: stainless steel 303


- **Finish:**

Handle: electrolytically polished stainless steel

Other components: polished stainless steel



stainless steel

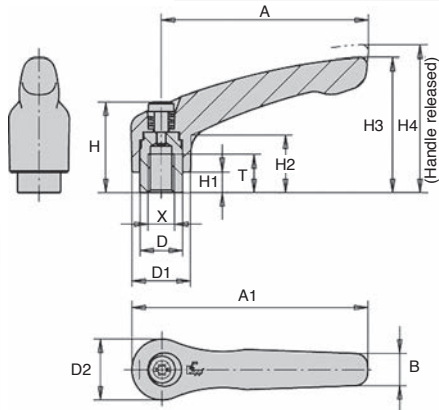

Pull the handle to unlock



DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread		D	D1	D2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each	
	X	T													Stock*	1 to 5
CLA01M5/SS	M5	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	✓	21,06 €
CLA01M6/SS	M6	9	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	-	21,06 €
CLA02M6/SS	M6	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	✓	28,38 €
CLA02M8/SS	M8	12	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	✓	28,38 €
CLA03M8/SS	M8	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	✓	34,19 €
CLA03M10/SS	M10	14	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	✓	34,19 €
CLA04M10/SS	M10	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	✓	40,03 €
CLA04M12/SS	M12	17	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	✓	40,03 €

*Depending on availability - Dimensions in mm

- **Stainless steel indexing handle with threaded shaft**

- **Materials:**



Precision cast handle: stainless steel 304

Other components: stainless steel 303

- **Finish:**

Handle: electrolytically polished stainless steel

Other components: polished stainless steel

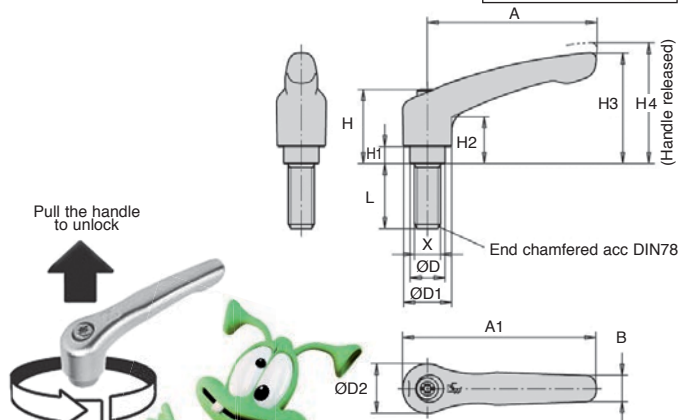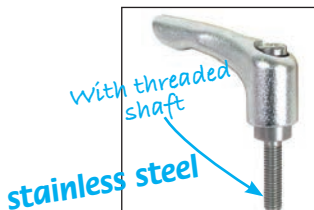

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread				H	H1	H2	H3	H4	A	A1	B	N° of teeth	Thread length L	Price each
	X	D	D1	D2											
CLA01T5/SS	M5	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	20	✓ 21,67 €
CLA01T6/SS	M6	10,0	13,0	14,0	24,5	4,0	14,5	31,0	34,0	40	47,0	7	16	30	✓ 21,67 €
CLA02T6/SS	M6	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓ 30,12 €
CLA02T8/SS	M8	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓ 30,12 €
CLA02T10/SS	M10	13,5	18,5	19,0	28,5	6,5	17,5	42,5	45,5	65	74,5	10	20	50	✓ 30,12 €
CLA03T8/SS	M8	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	50	✓ 36,16 €
CLA03T10/SS	M10	16,0	21,0	22,0	37,0	10,0	24,0	54,5	58,5	80	91,0	11	22	50	✓ 36,16 €
CLA04T12/SS	M12	19,0	27,0	27,5	43,0	10,0	27,0	63,0	67,5	95	109,0	13	24	50	✓ 42,45 €

*Depending on availability - Dimensions in mm

Our other products



PCF4

Conical flexible mount, Square base plate



ACL-APB

Closing system for aluminium profile, Magnetic door stop



UTKpwc

Utilitrac® 3 wheels carriage, Polymer series V wheels



DCA

Suction cup, 1.5 bellows, natural rubber



 
RFVcap

Stainless steel protective cover, Open protective cover



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane



PM3

Worm and wheel set, Machined plastic (delrin)



LRRR

Latch with locking system, Aluminium



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane



NT122

Spur gear coaxial gearbox, from 32 to 85 Nm - In-line



PGMT

Pull handle, Steel



BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...

Complementary products



CLB_T

Die cast zinc clamping lever - male, Zamak



PCLA_T

Technopolymer clamping lever - male, Plastic



CLB_M

Die cast zinc clamping lever - female, Zamak



PCLA_M

Technopolymer clamping lever - female, Plastic