



- Indexing lever with male thread and collar for a sealing washer

- EHEDG certification

- Material:

Stainless steel 1.4404 (316L)

Polished finish up to Ra<0.04

Advantages


- Intended for use in hygienic environments. The completely sealed handle and a gasket prevent contamination inside the lever.
- In addition, the insert is fitted with a conical collar so that the screwed connection can be hygienically sealed to the sealing washer.
- The lever rotates freely when not in use.

Accessory

- RDE sealing washers (cf. pages 37 à 39)



Apply pressure to engage the lever (safety feature)

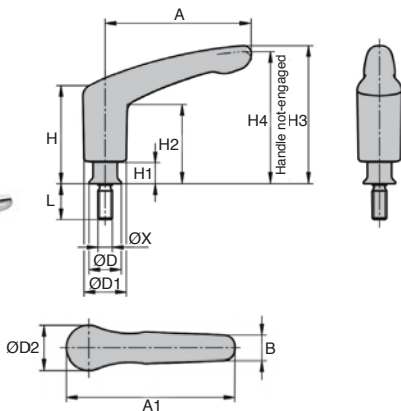

DISCOUNTS

Qty	1+	5+	10+
Disc.	Net	-5%	On request

Part N°	ØX	L	ØD	ØD1	ØD2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each 1 to 4
CLA03T8/HUSS	M8	30	18	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	71,61 €
CLA03T10/HUSS	M10	40	22,3	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	75,22 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

45

Our other products



GGB

Female wing knob,
With blind thread



CLR

Straight clevis,
Straight clevis for use
with a male clevis



FF15

Offset spur gear
reducer, from 2.20 to
10 Nm



G0

Steel spur gear, Steel
20NCD2



CMAss

Eye bolt stainless
steel, Stainless steel



J53

Spur gear coaxial
gearbox, from 0.43 to
1.15 - Inline



PML

Solid foot mount for
heavy loads, Ø 100,
120 or 150



CLM

Male clevis end,
Stainless steel short



PRF_T

Corner reinforcement,
Corner reinforcement



SBF

Sealed flange bearing
unit for Food Industry,
cover



MHXred

Reducing sleeve
male/female,
Hexagonal - steel



T10_21N1F

T type timing pulley,
Economy range - T10
moulded plastic
(nylon)

Complementary products



RDE-W

Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



RDE-B

Sealing washer
Hygienic Usit®,
Stainless steel - Blue
EPDM



CLA

Clamping lever
Hygienic Usit® -
female, Stainless steel