

- Indexing lever with male thread and collar for a sealing washer

- EHEDG certification
- Material:
Stainless steel 1.4404 (316L)
Polished finish up to Ra<0.04

Advantages


- Intended for use in hygienic environments. The completely sealed handle and a gasket prevent contamination inside the lever.
- In addition, the insert is fitted with a conical collar so that the screwed connection can be hygienically sealed to the sealing washer.
- The lever rotates freely when not in use.

Accessory

- RDE sealing washers
(cf. pages 37 à 39)



Apply pressure to engage the lever (safety feature)

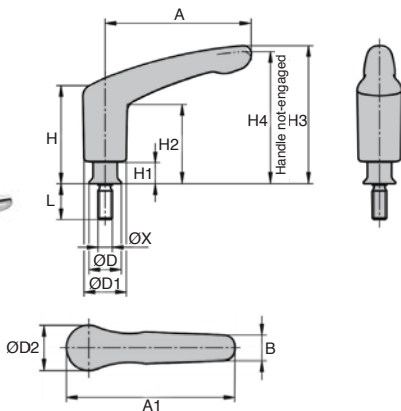

DISCOUNTS

Qty	1+	5+	10+
Disc.	Net	-5%	On request

Part N°	ØX	L	ØD	ØD1	ØD2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each
															1 to 4
CLA03T8/HUSS	M8	30	18	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	71,61 €
CLA03T10/HUSS	M10	40	22,3	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	75,22 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Our other products



UGH20

H Type Guide units,
For Ø20 actuators



PRF_PL_4590

Joining plate for
aluminium profile,
joint plate - 45x90
mm



GE_ET_2RS

Spherical bushing,
Hard chromium /
Teflon contact with
seals



NK40

Drylin®N miniature
guiding system, Width
40 mm



DOMI120

Accessories, Clamping
lever



DOMI120

Connecting kits, XZ
linking kit



SRG

Adjustable latch
clamp with strike
plate, Stroke from
78mm to 90mm



BPFLss

Pressed stainless
steel flange bearing,
Stainless steel




RLX

Free running conveyor
roller, PVC



GAL_20

 Conveyor roller for
Ø20mm spindle, Self-



HD


Double needle roller
universal joint, Heavy



WS10

Drylin® W rail, Rail

 Complementary products



RDE-W

Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



RDE-B

Sealing washer
Hygienic Usit®,
Stainless steel - Blue
EPDM



CLA

Clamping lever
Hygienic Usit® -
female, Stainless steel