

- Indexing lever with male thread and collar for a sealing washer

- EHEDG certification
- Material:
Stainless steel 1.4404 (316L)
Polished finish up to Ra<0.04

Advantages


- Intended for use in hygienic environments. The completely sealed handle and a gasket prevent contamination inside the lever.
- In addition, the insert is fitted with a conical collar so that the screwed connection can be hygienically sealed to the sealing washer.
- The lever rotates freely when not in use.

Accessory

- RDE sealing washers
(cf. pages 37 à 39)



Apply pressure to engage the lever (safety feature)

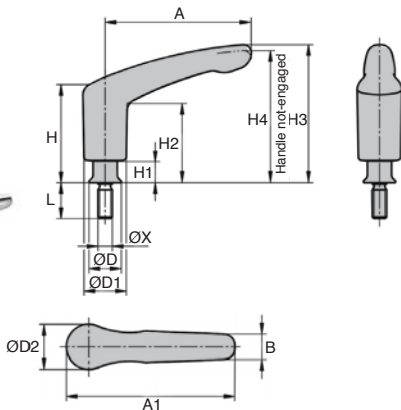

DISCOUNTS

Qty	1+	5+	10+
Disc.	Net	-5%	On request

Part N°	ØX	L	ØD	ØD1	ØD2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each
															1 to 4
CLA03T8/HUSS	M8	30	18	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	71,61 €
CLA03T10/HUSS	M10	40	22,3	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	75,22 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



BOX-TOR-H

Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00




PW_PWG2

Wheel - precision range, Bronze



ADSR

Backlash free coupling Gerwah®, from 12.5 to 525Nm

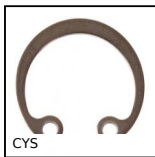

CYS

Internal circlip DIN472, internal DIN 472



CLM

Male clevis end, Steel short



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



NT61

Spur gear coaxial gearbox, from 5 to 14 Nm - Inline



METC

Flanged sintered bronze bush, Self-lubricating sintered bronze



HLA24

Right angle spiro bevel gearbox, Up to



PRF4590_E

Bracket for aluminium profile, PRF4590



DEP

Tools Hygienic Usit® and Hygienic



PW_PWG2

Worm - precision range, Stainless steel

Complementary products



RDE-W

Sealing washer Hygienic Usit®, Stainless steel - White EPDM



RDE-B

Sealing washer Hygienic Usit®, Stainless steel - Blue EPDM



CLA

Clamping lever Hygienic Usit® - female, Stainless steel