

Clamp lever



CLBM CLBMSS

- Clamp lever with threaded insert


- Materials:

Handle: diecast zinc, complies with DIN 1743

- Finish:

Steel: blackened steel

Handle : black plastic coating

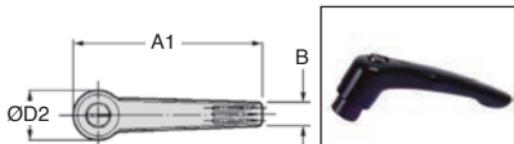


Uses

- The lever is normally in a locked position
- Raise the handle to release the lever and turn to required position
- When handle is released, lever will automatically lock in new position

Info.

- H4 = clearance height required for handle

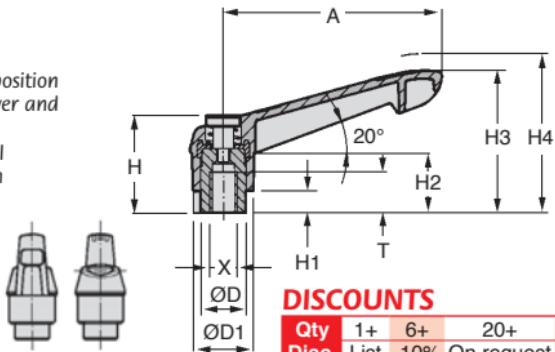

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	Thread	X	T	ØD	ØD1	ØD2	H	H1	H2
CLB01M4	M4	9	10,0	13,0	14,5	24,5	4,0	15,0	
CLB01M5	M5	9	10,0	13,0	14,5	24,5	4,0	15,0	
CLB01M6	M6	9	10,0	13,0	14,5	24,5	4,0	15,0	
CLB02M6	M6	12	13,5	18,0	19,5	28,5	6,5	17,5	
CLB02M8	M8	12	13,5	18,0	19,5	28,5	6,5	17,5	
CLB03M8	M8	14	16,0	21,5	23,0	37,0	10,0	24,0	
CLB03M10	M10	14	16,0	21,5	23,0	37,0	10,0	24,0	
CLB04M10	M10	17	19,0	25,5	27,5	43,0	10,0	26,0	
CLB04M12	M12	17	19,0	25,5	27,5	43,0	10,0	26,0	
CLB05M12	M12	23	23,0	30,0	32,5	49,0	12,0	33,0	
CLB05M16	M16	23	23,0	30,0	32,5	49,0	12,0	33,0	

Part number	Steel	Stainless	H3	H4	A	A1	B	N° of teeth	Stock*	Prix Uni. 1 à 5
									Steel	
CLB01M4	-		30,0	33,5	40	47,0	7,5	16	✓	- 11,46 € -
CLB01M5	CLB01M5SS		30,0	33,5	40	47,0	7,5	16	✓	- 11,46 € 16,07 €
CLB01M6	CLB01M6SS		30,0	33,5	40	47,0	7,5	16	✓	- 11,46 € 16,07 €
CLB02M6	CLB02M6SS		41,5	45,5	65	75,0	9,5	20	✓	✓ 14,48 € 19,93 €
CLB02M8	CLB02M8SS		41,5	45,5	65	75,0	9,5	20	✓	- 14,48 € 19,93 €
CLB03M8	CLB03M8SS		53,5	58,0	80	91,5	11,0	22	✓	- 15,82 € 22,63 €
CLB03M10	CLB03M10SS		53,5	58,0	80	91,5	11,0	22	✓	- 15,82 € 22,63 €
CLB04M10	CLB04M10SS		61,0	66,0	95	109,0	13,0	24	✓	- 17,90 € 29,44 €
CLB04M12	CLB04M12SS		61,0	66,0	95	109,0	13,0	24	✓	✓ 17,90 € 29,44 €
CLB05M12	CLB05M12SS		72,0	77,0	110	126,0	15,5	26	✓	- 22,23 € 35,83 €
CLB05M16	CLB05M16SS		72,0	77,0	110	126,0	15,5	26	✓	- 22,23 € 35,90 €

*Depending on availability - Dimensions in mm

Our other products



SER69K

Quarter turn latch for the food industry,
Stainless steel



INS100

Self tapping inserts-
coarse thread, Coarse
thread



VRM

Female swivelling
lifting rings, Female
swivelling



BAP25

Plastic clamping
collar, Ø25 - Ø40



PR125

Articulated foot Ø123,
Ø 123



PTCR

Adjustable furniture
foot, square tube



PRF_FIX_STD

Fastener for
aluminium profile,
Standard fastener



NCT

Square tube
connector, Fixed
angle



T2

T type timing belt,
T2.5 Steel cored



AT5M_AT10M

AT type timing belt
per metre, AT10 Steel



BCM_MPBT

Modular cylindrical
brush, PBT polyester



MHPGR

Arm with folding
rotating handle,

Complementary products



PCLA_M

Technopolymer
clamping lever -
female, Plastic



CLASS

Stainless steel
indexing handle -
female, Stainless steel



CLB_T

Die cast zinc clamping
lever - male, Zamak



CLASS

Stainless steel
indexing handle -
male, Stainless steel