

With male thread

CLBT
CLBTss

- Clamp lever with male thread and flattened end according to DIN 78

Materials:

Insert: steel (class 5.8) or

 
stainless steel (303)

Handle: diecast zinc,

complies with DIN 1743

- Finish: Blackened steel

With threaded shaft



Uses


- The lever is normally in a locked position
- Raise the handle to release the lever and turn to required position
- When handle is released, lever will automatically lock in new position

Options

- Alternate lengths of threaded shaft available for orders of more than 10 pieces

Info.

- H4 = clearance height required for handle

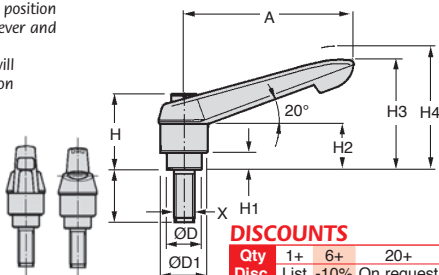

DISCOUNTS

| Qty | 1+ | 6+ | 20+ |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number | | Threaded rod X | H1 | L | | ØD | ØD1 | ØD2 |
|-------------|------------|----------------|------|-------|-----------|------|------|------|
| Steel | Stainless | | | Steel | Stainless | | | |
| CLB01T5 | CLB01T5SS | M5 | 4,0 | 50 | 25 | 10,0 | 13,0 | 14,5 |
| CLB01T6 | CLB01T6SS | M6 | 4,0 | 50 | 50 | 10,0 | 13,0 | 14,5 |
| CLB02T8 | CLB02T8SS | M8 | 6,5 | 60 | 60 | 13,5 | 18,0 | 19,5 |
| CLB02T10 | CLB02T10SS | M10 | 6,5 | 60 | 60 | 13,5 | 18,0 | 19,5 |
| CLB03T10 | CLB03T10SS | M10 | 10,0 | 60 | 60 | 16,0 | 21,5 | 23,0 |
| CLB04T10 | - | M10 | 10,0 | 90 | - | 19,0 | 25,5 | 27,5 |
| CLB04T12 | CLB04T12SS | M12 | 10,0 | 90 | 60 | 19,0 | 25,5 | 27,5 |
| CLB05T12 | - | M12 | 12,0 | 90 | - | 23,0 | 30,0 | 32,5 |
| CLB05T16 | CLB05T16SS | M16 | 12,0 | 90 | 60 | 23,0 | 30,0 | 32,5 |

| Part number | | H | | | | A | | | N° of teeth | Stock* | | Price each 1 to 5 | |
|-------------|------------|------|------|------|------|-----|-------|------|-------------|--------|-----|-------------------|-----------|
| Steel | Stainless | H | H2 | H3 | H4 | A | A1 | B | | Steel | Sts | Steel | Stainless |
| CLB01T5 | CLB01T5SS | 24,5 | 15,0 | 30,0 | 33,5 | 40 | 47,0 | 7,5 | 16 | ✓ | ✓ | 13,26 € | 17,02 € |
| CLB01T6 | CLB01T6SS | 24,5 | 15,0 | 30,0 | 33,5 | 40 | 47,0 | 7,5 | 16 | ✓ | ✓ | 13,26 € | 18,30 € |
| CLB02T8 | CLB02T8SS | 28,5 | 17,5 | 41,5 | 45,5 | 65 | 75,0 | 9,5 | 20 | ✓ | ✓ | 16,40 € | 22,71 € |
| CLB02T10 | CLB02T10SS | 28,5 | 17,5 | 41,5 | 45,5 | 65 | 75,0 | 9,5 | 20 | ✓ | ✓ | 16,40 € | 22,63 € |
| CLB03T10 | CLB03T10SS | 37,0 | 24,0 | 53,5 | 58,0 | 80 | 91,5 | 11,0 | 22 | ✓ | ✓ | 18,15 € | 25,85 € |
| CLB04T10 | - | 43,0 | 26,0 | 61,0 | 66,0 | 95 | 109,0 | 13,0 | 24 | ✓ | - | 21,68 € | - |
| CLB04T12 | CLB04T12SS | 43,0 | 26,0 | 61,0 | 66,0 | 95 | 109,0 | 13,0 | 24 | ✓ | ✓ | 18,15 € | 33,25 € |
| CLB05T12 | - | 49,0 | 33,0 | 72,0 | 77,0 | 110 | 126,0 | 15,5 | 26 | ✓ | - | 27,29 € | - |
| CLB05T16 | CLB05T16SS | 49,0 | 33,0 | 72,0 | 77,0 | 110 | 126,0 | 15,5 | 26 | ✓ | - | 27,29 € | 42,42 € |

*Depending on availability - Dimensions in mm

Our other products



PW_PWG1

Worm - precision range, Stainless steel



CHT

Asynchronous AC Motor, 0.55 to 1.1kW



PARF110

Pressed steel base rigid foot, Swivelling Ø110



HLUMss

Revolving handle for handwheel, Stainless steel 316



BABTV

Ball lock pins lockable, Stainless steel



PGM86-M5

Pull handle, Thermoplastic



M

Bellows cover, Accessory:



CHTRB

Single and dual output gearboxes, Up to 53,1 Nm



PLA

Flat magnet, Flat magnet with threaded hole



YG2

HEAVY DUTY spur gear, Steel 35NCD6



BUH77

Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



CFF_SS

Female rod ends DIN ISO12240-4, Stainless steel / bronze - Economy r...

Complementary products



PCLA_T

Technopolymer clamping lever - male, Plastic



CLASS

Stainless steel indexing handle - male, Stainless steel



CLB_M

Die cast zinc clamping lever - female, Zamak



CLASS

Stainless steel indexing handle - female, Stainless steel