

With male thread

CLBT
CLBTss

- Clamp lever with male thread and flattened end according to DIN 78

- Materials:

Insert: steel (class 5.8) or

 
stainless steel (303)

Handle: diecast zinc,

complies with DIN 1743

- Finish: Blackened steel

With threaded
shaft



Uses


- The lever is normally in a locked position
- Raise the handle to release the lever and turn to required position
- When handle is released, lever will automatically lock in new position

Options

- Alternate lengths of threaded shaft available for orders of more than 10 pieces

Info.

- H4 = clearance height required for handle

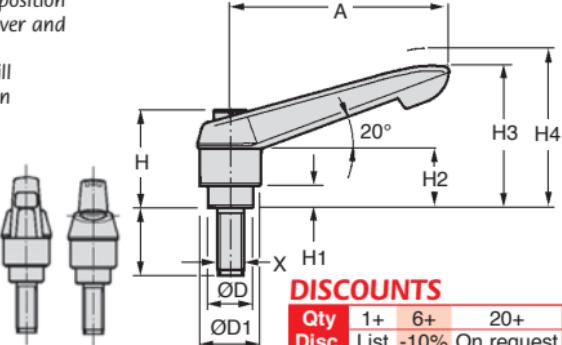

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10% On request	

Part number	Steel	Stainless	Threated rod X	H1	Steel	L	Stainless	ØD	ØD1	ØD2
CLB01T5	CLB01T5SS		M5	4,0	50	25	10,0	13,0	14,5	
CLB01T6	CLB01T6SS		M6	4,0	50	50	10,0	13,0	14,5	
CLB02T8	CLB02T8SS		M8	6,5	60	60	13,5	18,0	19,5	
CLB02T10	CLB02T10SS		M10	6,5	60	60	13,5	18,0	19,5	
CLB03T10	CLB03T10SS		M10	10,0	60	60	16,0	21,5	23,0	
CLB04T10	-		M10	10,0	90	-	19,0	25,5	27,5	
CLB04T12	CLB04T12SS		M12	10,0	90	60	19,0	25,5	27,5	
CLB05T12	-		M12	12,0	90	-	23,0	30,0	32,5	
CLB05T16	CLB05T16SS		M16	12,0	90	60	23,0	30,0	32,5	

Part number	Steel	Stainless	H	H2	H3	H4	A	A1	B	N° of teeth	Stock*	Price each 1 to 5	
	Steel	Stainless								Steel	Stns	Steel	Stainless
CLB01T5	CLB01T5SS		24,5	15,0	30,0	33,5	40	47,0	7,5	16	✓	✓	13,26 € 17,02 €
CLB01T6	CLB01T6SS		24,5	15,0	30,0	33,5	40	47,0	7,5	16	✓	✓	13,26 € 18,30 €
CLB02T8	CLB02T8SS		28,5	17,5	41,5	45,5	65	75,0	9,5	20	✓	✓	16,40 € 22,71 €
CLB02T10	CLB02T10SS		28,5	17,5	41,5	45,5	65	75,0	9,5	20	✓	✓	16,40 € 22,63 €
CLB03T10	CLB03T10SS		37,0	24,0	53,5	58,0	80	91,5	11,0	22	✓	✓	18,15 € 25,85 €
CLB04T10	-		43,0	26,0	61,0	66,0	95	109,0	13,0	24	✓	-	21,68 € -
CLB04T12	CLB04T12SS		43,0	26,0	61,0	66,0	95	109,0	13,0	24	✓	✓	21,68 € 33,25 €
CLB05T12	-		49,0	33,0	72,0	77,0	110	126,0	15,5	26	✓	✓	27,29 € -
CLB05T16	CLB05T16SS		49,0	33,0	72,0	77,0	110	126,0	15,5	26	✓	-	27,29 € 42,42 €

*Depending on availability - Dimensions in mm

Our other products



RFK38B

Hypoid gearbox -
Stainless steel, up to
200 Nm



PCS25ECO

Chain sprocket - steel,
6.35mm



BDP1R

Adjustable support
arm, Single clamp



RFK58B

Hypoid gearbox -
Stainless steel, up to
500 Nm



CTss

Universal joint,
telescopic, Inox, Light
duty



GG2

Ground spur gear,
Heat treated steel



VHTM

Hexagonal headed
screw Hygienic
Design®, Stainless
steel



J65

Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - Inline



NT122

Spur gear coaxial
gearbox, from 32 to
85 Nm - Inline




BOX-TOR-H

Box set of Nitrile O-
rings in nitrile, 3.00 x
2.00mm to 45.20 x



RFVcap

Stainless steel
protective cover,
Open protective cover

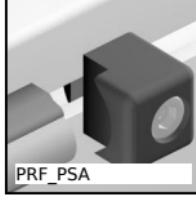

PRF_PSA

Shaft support for
aluminium profile,
Shaft stop

Complementary products



PCLA_T

Technopolymer
clamping lever - male,
Plastic



CLASS

Stainless steel
indexing handle -
male, Stainless steel



PCLA_T

Technopolymer
clamping lever - male,
Plastic



PCLA_M

Technopolymer
clamping lever -
female, Plastic