

## Nylon 6 moulded


## Module 1.5

- Moulded parts
- Pressure angle 20°
- Material:  
Nylon 6 Reinforced with 30% glass fibres

### Options

- Alternative number of teeth, a datasheet is available from [www.hpceurope.com](http://www.hpceurope.com) in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

$\phi A$ : Pre-bored hole must be finished

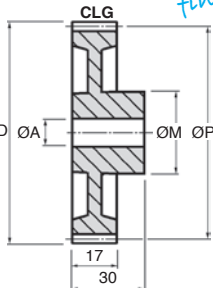

**Economy range**

### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	Number of teeth	Outside OD	PCD OP	Hub OM	Bore OA	Stock*	Price each 1 to 9
CLG1.5-12	12	21,0	18,0	14	5	✓	3,91 €
CLG1.5-15	15	25,5	22,5	18	5	✓	3,91 €
CLG1.5-16	16	27,0	24,0	18	5	-	On request
CLG1.5-18	18	30,0	27,0	18	5	-	On request
CLG1.5-20	20	33,0	30,0	25	8	✓	4,54 €
CLG1.5-24	24	39,0	36,0	28	8	✓	4,93 €
CLG1.5-25	25	40,0	37,5	30	8	-	4,93 €
CLG1.5-28	28	45,0	42,0	30	8	-	On request
CLG1.5-30	30	48,0	45,0	35	12	✓	6,12 €
CLG1.5-32	32	51,0	48,0	35	12	-	On request
CLG1.5-36	36	57,0	54,0	35	16	✓	8,90 €
CLG1.5-38	38	60,0	57,0	35	16	-	On request
CLG1.5-40	40	63,0	60,0	40	16	✓	8,90 €
CLG1.5-42	42	66,0	63,0	45	16	-	On request
CLG1.5-45	45	70,5	67,5	45	16	-	On request
CLG1.5-50	50	78,0	75,0	45	16	✓	11,12 €
CLG1.5-54	54	84,0	81,0	50	20	-	On request
CLG1.5-55	55	85,5	82,5	50	20	-	On request
CLG1.5-60	60	93,0	90,0	60	20	✓	14,50 €
CLG1.5-65	65	100,0	97,5	60	20	-	On request
CLG1.5-70	70	108,0	105,0	60	20	✓	20,69 €
↓ <b>Gears available up to this size</b> ↓							
<b>CLG1.5-75</b>	<b>75</b>	<b>115,5</b>	<b>112,5</b>	<b>60</b>	<b>20</b>	-	On request

\*Depending on availability - Dimensions in mm

## Our other products



BS3

Panamech, Multi-Beam stainless steel, Stainless steel - with set screw



EKGS

Backlash free coupling Gerwah®, from 0.5 to 35Nm



PDD

Actuating plunger, Non-rotating detector shaft



BHEX

Hexagonal cap, Black technopolymer



P55

Worm and wheel gear reducer, up to 57 Nm



PWC

Powercoil thread inserts, Kit Powercoil - with or without insertion ...




IN2

Internal gear, Steel 20NCD2



NIN

 Self-locking nut, A2 Stainless steel




GMK17\_P

Flat Guide, Flat guide for conical profile



PDR-RD

 Mounting feet with integrated castors,



M2

Worm and wheel set, Bronze



GE

Toggle latches, Miniature

## Complementary products



ZG1

Plastic spur gear, Machined plastic (delrin)