

Moulded plastic spur gear



Module

Nylon 6 moulded

1.0




- Moulded parts
- Pressure angle 20°
- Material:
Nylon 6, Reinforced with 30% glass fibres

Options

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

A: Pre-bored hole must be finished

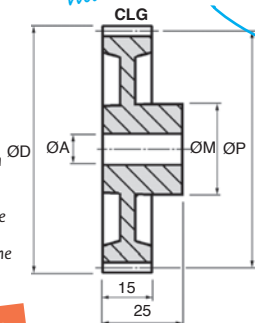

Economy range

DISCOUNTS

Qty	1+	10+	10+	100+	1000+
Disc.	List	-10%	-25%	-35%	On request

Part number	No. of teeth	Outside ØD	PCD ØP	Boss ØM	Bore ØA	Stock*	Price each 1 to 9
CLG1-12	12	14	12	9	4	✓	3,73 €
CLG1-15	15	17	15	10	4	✓	3,73 €
CLG1-16	16	18	16	13	5	✓	3,91 €
CLG1-20	20	22	20	16	5	✓	3,91 €
CLG1-24	24	26	24	20	6	✓	4,11 €
CLG1-25	25	27	25	20	6	✓	4,11 €
CLG1-28	28	30	28	22	6	✓	5,11 €
CLG1-30	30	32	30	25	6	✓	5,11 €
CLG1-32	32	34	32	25	6	✓	5,31 €
CLG1-35	35	37	35	30	8	✓	5,31 €
CLG1-40	40	42	40	30	8	✓	6,29 €
CLG1-45	45	47	45	35	10	✓	6,71 €
CLG1-50	50	52	50	35	10	✓	7,50 €
CLG1-55	55	57	55	35	14	✓	8,10 €
CLG1-60	60	62	60	40	14	✓	9,12 €
CLG1-70	70	72	70	40	20	✓	10,52 €
CLG1-72	72	74	72	40	20	✓	10,52 €
CLG1-75	75	77	75	50	20	-	On request
Gears available up to this size							
CLG1-77	77	79	77	50	20		On request

*Depending on availability - Dimensions in mm

Our other products



PRF-SCREEN-1

Screen support, Basic support



PR880

Idler sprocket for slat top chain, Range 880



G0

Steel spur gear, Steel 20NCD2



DOMI80

Accessories, Plate



PCatherm

Pull handle, Thermoplastic



AT10-BAR

AT type tooth bar stock, AT10



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



SHSS

Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



MHQMEP

Arm with rotating handle, Square bore



RTL450

Self-centering locking assembly, High torque



CLLCLLP

Clevis components, long version, Steel -



BAG-MI

Split shaft collar with clamp lever, Steel

Complementary products



ZG1

Plastic spur gear, Machined plastic (delrin)