



Spur gear for use in food industry


Module 1,5

Moulded blue PA6 Nylon

- Moulded gear for use in food applications
- Pressure angle: 20°
- Material:
Blue glass-fibre reinforced Polyamide

Info

- *Pre-bore after de-moulding, must be machined before installation.
- Alternative numbers of teeth (up to 120) possible but minimum quantity applies.
- We are unable to modify these products

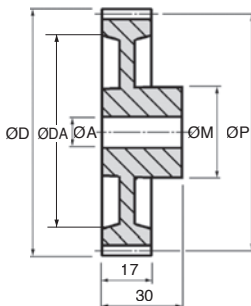

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	Net	-10%	-15%	-25%	On request

Part N°	Z	ØP PCD	ØD External	ØM Hub	ØA* Pre-bore	ØDA	Transmissible torque (Nm)	Price each. 1 to 9
CLG1.5-12/ALI	12	18,0	21,0	14	5	-	6,3	4,23 €
CLG1.5-15/ALI	15	22,5	25,5	18	5	-	7,9	4,32 €
CLG1.5-20/ALI	20	30,0	33,0	25	8	-	10,5	5,45 €
CLG1.5-25/ALI	25	37,5	40,5	30	8	-	13,2	6,16 €
CLG1.5-30/ALI	30	45,0	48,0	35	12	-	15,8	6,89 €
CLG1.5-36/ALI	36	54,0	57,0	35	12	-	19,0	9,65 €
CLG1.5-40/ALI	40	60,0	63,0	40	16	48	21,1	11,80 €
CLG1.5-50/ALI	50	75,0	78,0	45	16	53	26,4	15,39 €
CLG1.5-60/ALI	60	90,0	93,0	55	20	73	31,6	20,87 €

All dimensions in mm


Our other products



ZBconique
Machined plastic
bevel gear, 1:1



LVT
Miniature motorised
actuator 4A, 4 ampers

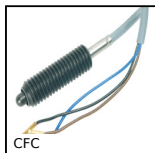

CFC
Spring loaded position
switch, Electric
contact



SHTC
Drylin® Linear table,
Maintenance free



RMSA
Adjustable shock-
absorber, Adjustable



UTKswc
Utilitrak® 3 wheels
carriage, Series V
precision steel wheel




BPM
Slotted spring plunger
with ball tip, Steel




SUA4_L
Chain link, Steel



EHD04
Internal epicyclic
servo reducers, from
3.4 to 7 Nm

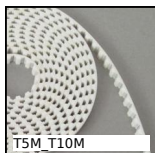

T5M_T10M
T type timing belt per
metre, T5 Steel cored
polyurethane

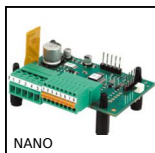

NANO
Speed controller 3A, 3
A



BCM_TP
Modular cylindrical
brush, Tampico
bristles

Complementary products



CLG1
Moulded plastic spur
gear, Moulded plastic
(nylon)



ZG1
Plastic spur gear,
Machined plastic
(delrin)