

Moulded plastic spur gear




Module 2.5

Nylon 6 **moulded**


- Moulded parts
- Pressure angle 20°
- Material:
Nylon 6, Reinforced with 30% glass fibres

Options

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

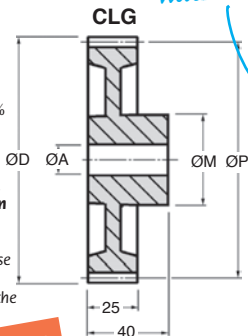

A: Pre-bored hole must be finished

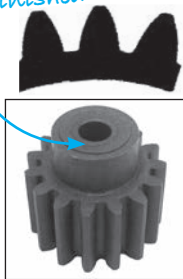

Economy range

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	No. of teeth	Outside OD	PCD OP	Boss OM	Bore OA	Stock*	Price each 1 to 9
CLG2.5-12	12	35,00	30,00	22	8	✓	6,29 €
CLG2.5-14	14	40,00	35,00	22	8	-	On request
CLG2.5-15	15	42,50	37,50	30	10	✓	6,29 €
CLG2.5-16	16	45,00	40,00	30	10	✓	9,12 €
CLG2.5-18	18	50,00	45,00	35	10	✓	9,12 €
CLG2.5-20	20	55,00	50,00	35	10	✓	9,12 €
CLG2.5-22	22	60,00	55,00	40	16	-	On request
CLG2.5-23	23	62,50	57,50	40	16	-	On request
CLG2.5-24	24	65,00	60,00	40	16	-	On request
CLG2.5-25	25	67,50	62,50	40	16	✓	12,50 €
CLG2.5-26	26	70,00	65,00	40	16	-	On request
CLG2.5-27	27	72,50	67,50	40	16	-	On request
CLG2.5-28	28	75,00	70,00	40	16	-	On request
CLG2.5-29	29	77,50	72,50	40	16	-	On request
CLG2.5-30	30	80,00	75,00	45	16	-	15,87 €
CLG2.5-32	32	85,00	80,00	50	16	-	On request
CLG2.5-35	35	92,50	87,50	50	16	-	18,90 €
CLG2.5-40	40	105,00	100,00	60	20	-	On request
CLG2.5-45	45	117,50	112,50	60	20	-	28,29 €
CLG2.5-50	50	130,00	125,00	60	20	✓	31,31 €
CLG2.5-57	57	147,50	142,50	60	20	-	On request
Gears available up to this size							↓
CLG2.5-62	62	160,00	155,00	60	25	-	On request

*Depending on availability - Dimensions in mm

Our other products



CDP
Flanged drill bushing,
Steel



SBF
Sealed flange bearing
unit for Food Industry,
cover



BAP
Plastic clamping
collar, Ø10 - Ø20



SH0
Parallel axis helical
gear, Steel 20NCD2



SER69K
Quarter turn latch for
the food industry,
Stainless steel



NT62
Spur gear coaxial
gearbox, from 6 to 18
Nm - In-line



BLHT50
Right angled gearbox,
from 11.50 to 30 Nm



PGNT
Thermoplastic T
handle, With threaded
insert



ZBconique
Machined plastic
bevel gear, 1:1



BLHB30
Right angled gearbox,
bored shafts, up to
4.4 Nm



T5M T10M
T type timing belt per
metre, T5 Steel cored
polyurethane



DOMI120
Domino 120
adjustable slide, Slide
DOMILINE 120

Complementary products



ZG2
Plastic spur gear,
Machined plastic
(delrin)



YG2
HEAVY DUTY spur
gear, Steel 35NCD6