

Moulded plastic spur gear




Module 2.5

Nylon 6 **moulded**


- Moulded parts
- Pressure angle 20°
- Material:
Nylon 6, Reinforced with 30% glass fibres

Options

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

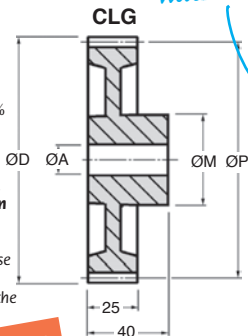

A: Pre-bored hole must be finished

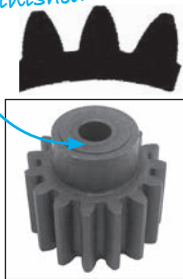

Economy range

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	No. of teeth	Outside OD	PCD OP	Boss OM	Bore OA	Stock*	Price each 1 to 9
CLG2.5-12	12	35,00	30,00	22	8	✓	6,29 €
CLG2.5-14	14	40,00	35,00	22	8	-	On request
CLG2.5-15	15	42,50	37,50	30	10	✓	6,29 €
CLG2.5-16	16	45,00	40,00	30	10	✓	9,12 €
CLG2.5-18	18	50,00	45,00	35	10	✓	9,12 €
CLG2.5-20	20	55,00	50,00	35	10	✓	9,12 €
CLG2.5-22	22	60,00	55,00	40	16	-	On request
CLG2.5-23	23	62,50	57,50	40	16	-	On request
CLG2.5-24	24	65,00	60,00	40	16	-	On request
CLG2.5-25	25	67,50	62,50	40	16	✓	12,50 €
CLG2.5-26	26	70,00	65,00	40	16	-	On request
CLG2.5-27	27	72,50	67,50	40	16	-	On request
CLG2.5-28	28	75,00	70,00	40	16	-	On request
CLG2.5-29	29	77,50	72,50	40	16	-	On request
CLG2.5-30	30	80,00	75,00	45	16	-	15,87 €
CLG2.5-32	32	85,00	80,00	50	16	-	On request
CLG2.5-35	35	92,50	87,50	50	16	-	18,90 €
CLG2.5-40	40	105,00	100,00	60	20	-	On request
CLG2.5-45	45	117,50	112,50	60	20	-	28,29 €
CLG2.5-50	50	130,00	125,00	60	20	✓	31,31 €
CLG2.5-57	57	147,50	142,50	60	20	-	On request
Gears available up to this size							↓
CLG2.5-62	62	160,00	155,00	60	25	-	On request

*Depending on availability - Dimensions in mm

Our other products



VBFP
Small 6 lobe threaded handle - female, Duroplast - Brass



CHTRP
Single and dual output gearboxes, Up to 87,3 Nm



SHN
Hexagonal nut, DIN934, Steel (Class 6|8)



EFTC
Fixing support, Stainless steel



M0
Worm and wheel set, Bronze



PTA100
Articulated levelling foot, pressed base Ø100, Ø 100



PGMSS
Stainless steel pull handle, Stainless steel



BAP25
Plastic clamping collar, Ø25 - Ø40



DB
Steel bevel gear, 2:1



AT5-10ECO
AT type timing pulley, Economy range - AT5



PRF_BR
Clamp for aluminium profile, Clamp for



HW_HT
Half-rail guide, Rail

Complementary products



ZG2
Plastic spur gear, Machined plastic (delrin)



YG2
HEAVY DUTY spur gear, Steel 35NCD6