




- Moulded parts
- Pressure angle 20°
- Material:
Nylon 6 Reinforced with 30% glass fibres

Options

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

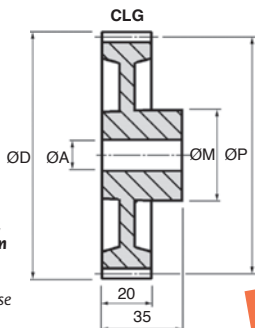

A: Pre-bored hole must be finished

Economy range

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	No. of teeth Outside	ØD PCD	ØP Boss	ØM Bore	ØA	Stock*	Price each 1 to 9
CLG2-12	12	28	24	18	8	✓	4.54 €
CLG2-15	15	35	30	22	8	✓	4.54 €
CLG2-16	16	36	32	25	8	✓	5.89 €
CLG2-20	20	44	40	30	10	✓	5.89 €
CLG2-24	24	52	48	35	10	✓	8.10 €
CLG2-25	25	54	50	35	10	✓	8.10 €
CLG2-26	26	56	52	40	14	-	On request
CLG2-30	30	64	60	40	14	✓	10.31 €
CLG2-32	32	68	64	45	16	✓	12.29 €
CLG2-34	34	72	68	45	16	-	On request
CLG2-35	35	74	70	45	16	-	On request
CLG2-36	36	76	72	50	16	✓	14.68 €
CLG2-40	40	84	80	50	16	✓	14.68 €
CLG2-45	45	94	90	60	16	-	On request
CLG2-48	48	100	96	60	16	-	On request
CLG2-50	50	104	100	60	20	✓	19.10 €
CLG2-60	60	124	120	60	20	✓	24.50 €
CLG2-65	65	134	130	60	20	✓	27.11 €
CLG2-70	70	144	140	60	20	✓	27.11 €
CLG2-72	72	148	144	60	20	-	On request
CLG2-75	75	154	150	60	20	-	On request
Gears available up to this size							
CLG2-78	78	160	156	60	25	-	On request

*Depending on availability - Dimensions in mm

Our other products



RBNpl

Swivel castor with double brake, Steel - rubber



RAG-12-M8

Roller guide accessory, Anchoring system



HRV

V-rail guidance Simple Select® system, Rail with carriage



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



 
BMM

Knurled knob - male, Knurled



TS01_TW01

Drylin® T linear slide, up to 7000 N



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



TK_UUOP

Topball self-aligning linear bearing, Topball self-aligning



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



ACM_AZ

Mounting bracket for bonnet fastener, Hook



UFX

Uneflex® elastic coupling, range



H2


Crossed helical gear crossed axis at 90°, Steel 20NCD2

Complementary products



ZG2

 Plastic spur gear, Machined plastic (delrin)



CRM

Moulded nylon rack, Nylon