




- Moulded parts
- Pressure angle 20°
- Material:  
Nylon 6 Reinforced with 30% glass fibres

### Options

- Alternative number of teeth, a datasheet is available from [www.hpceurope.com](http://www.hpceurope.com) in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

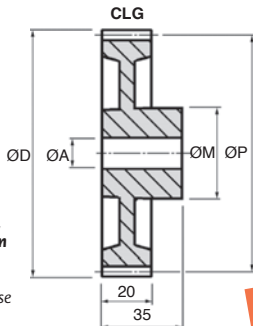

A: Pre-bored hole must be finished

**Economy range**

 
### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	No. of teeth Outside	ØD PCD	ØP Boss	ØM Bore	ØA	Stock*	Price each 1 to 9
CLG2-12	12	28	24	18	8	✓	4.54 €
CLG2-15	15	35	30	22	8	✓	4.54 €
CLG2-16	16	36	32	25	8	✓	5.89 €
CLG2-20	20	44	40	30	10	✓	5.89 €
CLG2-24	24	52	48	35	10	✓	8.10 €
CLG2-25	25	54	50	35	10	✓	8.10 €
CLG2-26	26	56	52	40	14	-	On request
CLG2-30	30	64	60	40	14	✓	10.31 €
CLG2-32	32	68	64	45	16	✓	12.29 €
CLG2-34	34	72	68	45	16	-	On request
CLG2-35	35	74	70	45	16	-	On request
CLG2-36	36	76	72	50	16	✓	14.68 €
CLG2-40	40	84	80	50	16	✓	14.68 €
CLG2-45	45	94	90	60	16	-	On request
CLG2-48	48	100	96	60	16	-	On request
CLG2-50	50	104	100	60	20	✓	19.10 €
CLG2-60	60	124	120	60	20	✓	24.50 €
CLG2-65	65	134	130	60	20	✓	27.11 €
CLG2-70	70	144	140	60	20	✓	27.11 €
CLG2-72	72	148	144	60	20	-	On request
CLG2-75	75	154	150	60	20	-	On request
<b>Gears available up to this size</b>							
CLG2-78	78	160	156	60	25	-	On request

\*Depending on availability - Dimensions in mm

## Our other products




BLHM50

Right angled gearbox, double output shafts, up to 30 Nm



SSDB

 Stainless steel bevel gear, 2:1



P30

Worm and wheel gear reducer, up to 8.80 Nm



M1

Worm and wheel set, Non hardened steel



CHM40

Worm and wheel gear reducer, up to 57 Nm



ASM

Cylindrical polymer bush, Food grade polymer



NT92

Spur gear coaxial gearbox, from 15 to 40 Nm - In-line



GMK17\_BR

Clamp for guiding profile, Rounded only - single



WTM

Tightening washer - DIN6340, Steel



BPFLss

Pressed stainless steel flange bearing,



LRR

Spring loaded latch, Spring loaded latch



CLB\_T


Die cast zinc clamping lever - male, Zamak

## Complementary products



ZG2

 Plastic spur gear, Machined plastic (delrin)



CRM

Moulded nylon rack, Nylon