



Spur gear for use in food industry


Module 2,5

Moulded blue PA6 Nylon

- Moulded gear for use in food applications
- Pressure angle: 20°
- Material:
Blue glass-fibre reinforced Polyamide

Info

- *Pre-bore after de-moulding, must be machined before installation.
- Alternative numbers of teeth possible up to 90 (Min quantity applies)
- We are unable to modify these products

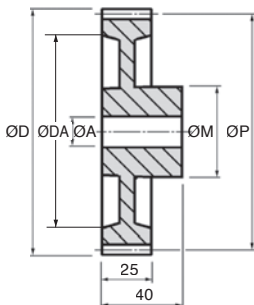

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	Net	-10%	-15%	-25%	On request

Part N°	Z	ØP PCD	ØD External	ØM Hub	ØA* Pre-bore	ØDA	Transmissible torque (Nm)	Price each. 1 to 9
CLG2.5-12/ALI	12	30,0	35,0	22	8	-	28,1	7,02 €
CLG2.5-15/ALI	15	37,5	42,5	30	10	-	35,1	7,66 €
CLG2.5-18/ALI	18	45,0	50,0	35	10	-	42,2	10,39 €
CLG2.5-20/ALI	20	50,0	55,0	35	10	-	46,8	10,91 €
CLG2.5-25/ALI	25	62,5	67,5	40	16	-	58,5	16,58 €
CLG2.5-30/ALI	30	75,0	80,0	45	16	56	70,3	21,86 €
CLG2.5-35/ALI	35	87,5	92,5	50	16	61	82,0	25,04 €
CLG2.5-40/ALI	40	100,0	105,0	50	18	73	93,7	30,78 €
CLG2.5-50/ALI	50	125,0	130,0	60	20	105	117,1	42,43 €

All dimensions in mm

Our other products



Brush strip per meter
PA6 fibres Ø0.3 to
Ø0.5, Black polyamide
6 -...



Die cast zinc clamping
lever - male, Zamak



Worm and wheel set,
Hardened steel



Pressed steel base
rigid foot, Swivelling -
Ø80



Plastic spur gear,
Machined plastic
(delrin)



Spur gear coaxial
gearbox, from 0.13 to
0.49 Nm - Inline



Accessories, Fixing kit



Deep groove ball
bearing, Steel



T type timing belt,
T10 Steel cored



Parallel axis helical
gear, Steel 20NCD2



Clip on Quarter turn
latch, Wing head



Double cross clamp,
Crossed

Complementary products



Moulded plastic spur
gear, Moulded plastic
(nylon)



Plastic spur gear,
Machined plastic
(delrin)