

Spur gear for use in food industry



Module 3,0

Moulded blue PA6 Nylon

- Moulded gear for use in food applications
- Pressure angle: 20°
- Material:


Blue glass-fibre reinforced Polyamide

Info

- *Pre-bore after de-moulding, must be machined before installation.
- Alternative numbers of teeth (up to 60) possible but minimum quantity applies
- **We are unable to modify these products**



Food industry

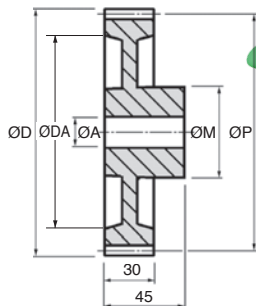

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	Net	-10%	-15%	-25%	On request

Part N°	Z	ØP PCD	ØD External	ØM Hub	ØA* Pre-bore	ØDA	Transmissible torque (Nm)	Price each. 1 to 9
CLG3-12/ALI	12	36	42	25	12	-	48,6	10,14 €
CLG3-15/ALI	15	45	51	30	12	-	60,7	12,47 €
CLG3-18/ALI	18	54	60	40	12	-	72,8	18,33 €
CLG3-20/ALI	20	60	66	45	12	-	80,9	19,83 €
CLG3-25/ALI	25	75	81	45	16	-	101,2	27,83 €
CLG3-30/ALI	30	90	96	50	16	65	121,4	36,54 €
CLG3-40/ALI	40	120	126	60	20	85	161,9	53,62 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

35

Our other products



PRF-SRA
Lock for aluminium
profile, Lock



RBNpl
Swivel castor with
double brake, Steel -
rubber



BCH_SS
Mushroom headed
button, M3 to M8



BABFCFO
Ball pin socket,
Mounting collar with a
oval flange




G3
Steel spur gear, Steel
20NCD2



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT10




CLG2
Moulded plastic spur
gear, Moulded plastic
(nylon)

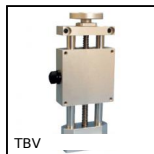

TBV
Manual lifting tables,
3kg



 PRF-CHAR-POU
Tool holder for
aluminium profile,
Moveable tool holder



CT
Telescopic universal
joint, Normal duty



DHX
Dowel pin internal
thread, Extractable
DIN 7979D



LSAG
Precision linear rotary
ball spline, Rail - from
514 N to 15386 N

Complementary products



CLG3
Moulded plastic spur
gear, Moulded plastic
(nylon)



ZG3
Plastic spur gear,
Machined plastic
(delrin)