


## Steel


## CLL CLLP

- Material: Medium hard steel 9S Mn Pb28, R= 500 N/mm<sup>2</sup>
- Conforms to DIN 71752
- **Not sold individually, please contact us for details**

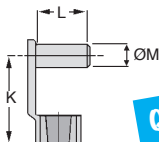


CLLP Clip

**Quick assembly**

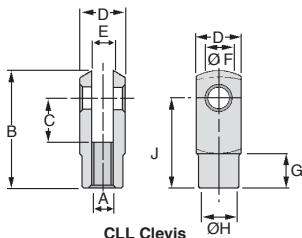

CLL Clevis

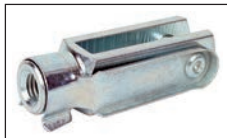

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-10%	-20%	-30%	-40%	On request

### Clevis

Part number	A	B	C	D	E (B13)	ØF (H9)	G	ØH	J	Static load Co (daN)	Stock*	Price each 1 to 5
CLL-5	M5 x 0,80	36	20	10	5	5	7,50	9	30	500	✓	1,68 €
CLL-6	M6 x 1,00	43	24	12	6	6	9,00	10	36	720	✓	1,80 €
CLL-8	M8 x 1,25	58	32	16	8	8	12,00	14	48	1280	✓	2,60 €
CLL-10	M10 x 1,5	72	40	20	10	10	15,00	18	60	2000	✓	4,34 €
CLL-12	M12 x 1,75	86	48	24	12	12	18,00	20	72	2880	✓	7,01 €

### Spring clip

Part number	K	L	ØM	Stock*	Price each 1 to 5
CLLP-5	29	12	5	✓	0,72 €
CLLP-6	35	14	6	✓	0,72 €
CLLP-8	47	19	8	✓	0,78 €
CLLP-10	59	23	10	✓	0,88 €
CLLP-12	71	28	12	✓	1,48 €

\*Depending on availability - Dimensions in mm

## Our other products



CHAE4060PA  
Decorative asymmetric screwed hinge, Polyamide



BAC105  
Storage bin, 8mm



BOX-TOR-A  
Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 28.17 x 3.53




PTMR  
Telescopic furniture foot, threaded stud




PGR  
Folding revolving handle for handwheel, Folding



 DOG258  
Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



 JFM  
Flanged polymer bush, Universal polymer



PRZ  
Wear strip for slat top chain, Z profile to be filled



E50  
Right angle helical reducers, from 3 to 41



GSI\_A  
Gas control screw for gas spring, Gas



SR  
Narrow spur rack, Stainless steel



NPTF30  
Fixed tube carrier, Fixed Ø14 to Ø20

## Complementary products



CLLCLLP  
Clevis components, long version, Steel - long version



CLSCLP  
Clevis components, short version, Steel - short range