


Steel


CLL CLLP

- Material: Medium hard steel 9S Mn Pb28, R= 500 N/mm²
- Conforms to DIN 71752
- **Not sold individually, please contact us for details**

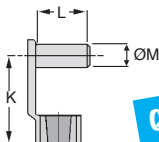

CLLP Clip

Quick assembly

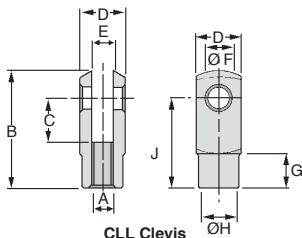

CLL Clevis



DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-10%	-20%	-30%	-40%	On request

Clevis

Part number	A	B	C	D	E (B13)	ØF (H9)	G	ØH	J	Static load Co (daN)	Stock*	Price each 1 to 5
CLL-5	M5 x 0,80	36	20	10	5	5	7,50	9	30	500	✓	1,68 €
CLL-6	M6 x 1,00	43	24	12	6	6	9,00	10	36	720	✓	1,80 €
CLL-8	M8 x 1,25	58	32	16	8	8	12,00	14	48	1280	✓	2,60 €
CLL-10	M10 x 1,5	72	40	20	10	10	15,00	18	60	2000	✓	4,34 €
CLL-12	M12 x 1,75	86	48	24	12	12	18,00	20	72	2880	✓	7,01 €

Spring clip

Part number	K	L	ØM	Stock*	Price each 1 to 5
CLLP-5	29	12	5	✓	0,72 €
CLLP-6	35	14	6	✓	0,72 €
CLLP-8	47	19	8	✓	0,78 €
CLLP-10	59	23	10	✓	0,88 €
CLLP-12	71	28	12	✓	1,48 €

*Depending on availability - Dimensions in mm

Our other products



RT61
Self-centering locking
Assembly,
Medium/low torque



T5-BAR
T type tooth bar
stock, T5



MRA
Quick link, Steel



NPTF30
Spacer for tube
carrier, Fixing
accessory Ø14 to Ø20



PGT
Sliding profile, Sliding
panel support



UGH50
H Type Guide units,
For Ø50 actuators



EBM
Steel U bolt, Steel



RBNpl
Swivel castor with
double brake, Steel -
rubber



BAC105
Storage bin, 8mm



BPM-Z
Plastic slotted spring
plunger with ball tip,



YG1
HEAVY DUTY spur
gear, Steel 35NCD6



SLB
Indexing plunger,
steel class 5.8

Complementary products



CLLCLLP
Clevis components,
long version, Steel -
long version



CLSCLP
Clevis components,
short version, Steel -
short range